

Idler for plate chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:

Low friction acetal
Stainless steel screws



- Operating temp.: -40°C to +85°C

(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

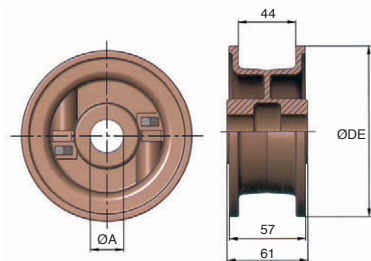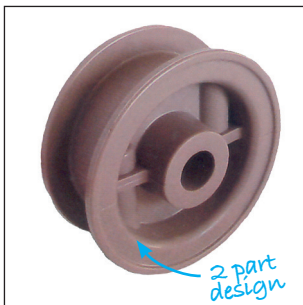

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	11,71 €
DBL820-21-30	129	30	0,3	11,71 €
DBL820-21-35	129	35	0,3	11,71 €
DBL820-21-40	129	40	0,3	11,71 €
DBL820-23-25	141	25	0,4	13,14 €
DBL820-23-30	141	30	0,4	13,14 €
DBL820-23-35	141	35	0,4	13,14 €
DBL820-23-40	141	40	0,4	13,53 €
DBL820-25-25	153	45	0,4	13,39 €
DBL820-25-30	153	30	0,4	13,39 €
DBL820-25-35	153	35	0,4	13,39 €
DBL820-25-40	153	40	0,4	13,39 €

Dimensions in mm

Altri prodotti...




E40

Riduttore a rinvio angolare, da 2.30 a 20 Nm



HTD5M_09

Puleggia dentata di trasmissione tipo HTD, HTD5 Alluminio

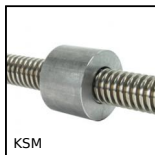

KSM

Dado cilindrico in acciaio, Acciaio - 1 filetto




BFDdII

Boccola di fermo per perno ad innesto, Acciaio nichelato



GET-AL

Giunto elastico alluminio serie eco., Alluminio

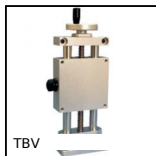

TBV

Tavola di posizionamento verticale manuale, 20kg



GDR880

Guida dritta, Serie 880 e 881



T5P_T10P

Piastra di giunzione per cinghia T, T10



KKP-AR

Manicotto a sfere inclinate, Carichi elevati / -20° +200°



MPB

Distanziatore esagonale, Ottone



ACM_AZ

Aggancio per tirante chiusura in gomma, Aggancio



PRF-SRA-78

Sistema di chiusura per profili alluminio, Serratura rapida autobloc...

Prodotti correlati



CAP820

Catena a tapparella dritta, Stretta serie 820



CAP815

Catena a tapparella dritta, Stretta serie 815



PT820

Pignone di trazione, Serie 820 e 815



PR820

Ruota di rinvio, Serie 820 e 815