

Idler for plate chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:

Low friction acetal
Stainless steel screws



- Operating temp.: -40°C to +85°C

(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

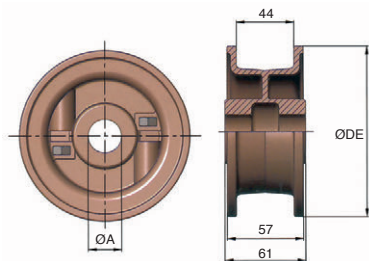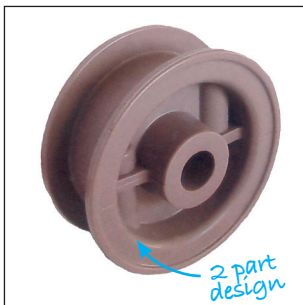

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	11,71 €
DBL820-21-30	129	30	0,3	11,71 €
DBL820-21-35	129	35	0,3	11,71 €
DBL820-21-40	129	40	0,3	11,71 €
DBL820-23-25	141	25	0,4	13,14 €
DBL820-23-30	141	30	0,4	13,14 €
DBL820-23-35	141	35	0,4	13,14 €
DBL820-23-40	141	40	0,4	13,53 €
DBL820-25-25	153	45	0,4	13,39 €
DBL820-25-30	153	30	0,4	13,39 €
DBL820-25-35	153	35	0,4	13,39 €
DBL820-25-40	153	40	0,4	13,39 €

Dimensions in mm

Altri prodotti...



CHAR6035

Cerniera a molla,
avvitabile e saldabile



PR40

Piede fissabile con
snodo - poliammide, Ø
50




CDP

Boccola di
posizionamento,
Acciaio



BABT

Perno autobloccante,
Inox temprato

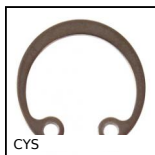

CYS

Anello di arresto
interno DIN472,
interno DIN 472



BPFLss

Supporto a flangia
ovale a carico leggero
inox, Inox



NDS14C

Porta ventosa,
Connettore angolare
universale



SNG

Cuscinetto ritto
polimero inox, Ghisa -
In 2 metà



GLT2-17

Guide telescopiche
per montaggio in



LR

Cuscinetti a sfere -
Accessorio, Ghiera di



DOMI30

Slitta di regolazione
Domino 30, Slitta



AT10-BAR

Barra dentata, AT10

Prodotti correlati



CAP820

Catena a tapparella
dritta, Stretta serie
820



CAP815

Catena a tapparella
dritta, Stretta serie
815



PT820

Pignone di trazione,
Serie 820 e 815



PR820

Ruota di rinvio, Serie
820 e 815