




Idler for slat top chain

For chain ranges 880 TAB and 881 TAB **DBL880**

- For use with CAP880T plate chains
- Materials:
 - Self lubricating acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

Accessory

- Plastic clamping ring BAP (tome 5 p.94-95)

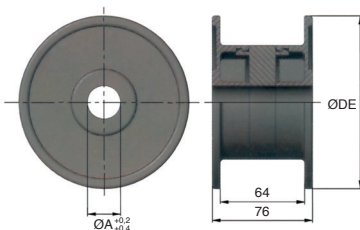

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	117	25	0,3	11,71 €
DBL880-19-30	117	30	0,3	11,71 €
DBL880-19-35	117	35	0,3	11,71 €
DBL880-19-40	117	40	0,3	11,71 €
DBL880-21-25	129	25	0,3	12,21 €
DBL880-21-30	129	30	0,3	12,21 €
DBL880-21-35	129	35	0,3	12,21 €
DBL880-21-40	129	40	0,3	12,21 €
DBL880-23-25	141	25	0,3	13,53 €
DBL880-23-30	141	30	0,3	13,53 €
DBL880-23-35	141	35	0,3	13,53 €
DBL880-23-40	141	40	0,3	13,43 €
DBL880-25-25	153	25	0,4	14,24 €
DBL880-25-30	153	30	0,4	14,24 €
DBL880-25-35	153	35	0,4	14,24 €
DBL880-25-40	153	40	0,4	14,24 €

Dimensions in mm

Altri prodotti...



VT

Limitatore di coppia ad attrito Vari-Tork®, 0.53 a 1.32 Nm



GG1

Ingranaggio dritto rettificato, Acciaio trattato



GG2

Ingranaggio dritto rettificato, Acciaio trattato



CHB

Riduttore a ruota e vite senza fine, fino a 22 Nm



UFX

Giunto elastico UNEFLEX, range



CHML50

Riduttore a ruota e vite senza fine, fino a 107 Nm - Con limitatore ...



CHMX_CHMDX

Albero per riduttore a ruota e vite senza fine CHMR e CHM, Albero se...



PRF-P

Supporto piede, Per piedi o ruote



MAX26

Motoriduttore DC 12V e 24V DC, da 0,075 a 0,6Nm



CHA35

Cerniera ad avvitare, Cerniera



CHAPAMss

Cerniera a testa piatta a saldare, Inox o Alluminio



VDSQCB

Bloccaggio scorrevole per la regolazione, Piastra di base per profil...

Prodotti correlati



CAP880

Catena a tapparella, Stretta serie 880



PR880

Ruota di rinvio, Serie 880