




Idler for slat top chain

For chain ranges 880 TAB and 881 TAB **DBL880**

- For use with CAP880T plate chains
- Materials:
 - Self lubricating acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

Accessory

- Plastic clamping ring BAP (tome 5 p.94-95)

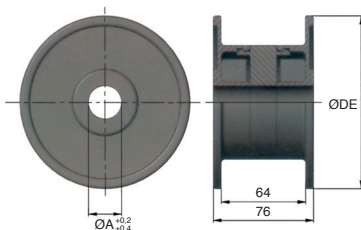

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	117	25	0,3	11,71 €
DBL880-19-30	117	30	0,3	11,71 €
DBL880-19-35	117	35	0,3	11,71 €
DBL880-19-40	117	40	0,3	11,71 €
DBL880-21-25	129	25	0,3	12,21 €
DBL880-21-30	129	30	0,3	12,21 €
DBL880-21-35	129	35	0,3	12,21 €
DBL880-21-40	129	40	0,3	12,21 €
DBL880-23-25	141	25	0,3	13,53 €
DBL880-23-30	141	30	0,3	13,53 €
DBL880-23-35	141	35	0,3	13,53 €
DBL880-23-40	141	40	0,3	13,43 €
DBL880-25-25	153	25	0,4	14,24 €
DBL880-25-30	153	30	0,4	14,24 €
DBL880-25-35	153	35	0,4	14,24 €
DBL880-25-40	153	40	0,4	14,24 €

Dimensions in mm

Altri prodotti...



RHTtcss
Ruota alte temperature, fino a 200kg



BOX-TOR-D
Valigetta di guarnizioni toriche in nitrile, 18.00 x 2.00mm a 50.00 ...



MDB_MTB
Ingranaggio conico in plastica stampata , 3:1



VRBS
Anello di sollevamento, Articolato - a saldare



VRC1
Staffa di bloccaggio 1 lato, 1 lato



BPVMss
Sfera portante avvitabile miniatura, Miniatura ad avvitare



MDB_MTB
Ingranaggio conico in plastica stampata, 2:1



SSDB
Ingranaggio conico inox, 2:1




CHAL3
Cerniera piana, Acciaio



AT10courroie
Cinghia di posizionamento AT,



PW_PWG3
Vite senza fine di precisione, Acciaio

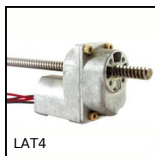

LAT4
Attuatore lineare a motore 4A, 4 ampere

Prodotti correlati



CAP880
Catena a tapparella, Stretta serie 880



PR880
Ruota di rinvio, Serie 880