




# Idler for slat top chain

For chain ranges 880 TAB and 881 TAB **DBL880**

- For use with CAP880T plate chains
- Materials:
  - Self lubricating acetal
- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

## Accessory

- Plastic clamping ring BAP (tome 5 p.94-95)

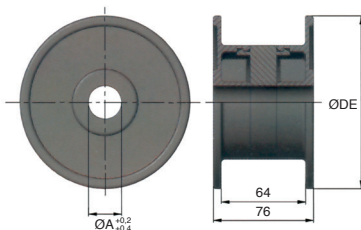

## DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	117	25	0,3	11,71 €
DBL880-19-30	117	30	0,3	11,71 €
DBL880-19-35	117	35	0,3	11,71 €
DBL880-19-40	117	40	0,3	11,71 €
DBL880-21-25	129	25	0,3	12,21 €
DBL880-21-30	129	30	0,3	12,21 €
DBL880-21-35	129	35	0,3	12,21 €
DBL880-21-40	129	40	0,3	12,21 €
DBL880-23-25	141	25	0,3	13,53 €
DBL880-23-30	141	30	0,3	13,53 €
DBL880-23-35	141	35	0,3	13,53 €
DBL880-23-40	141	40	0,3	13,43 €
DBL880-25-25	153	25	0,4	14,24 €
DBL880-25-30	153	30	0,4	14,24 €
DBL880-25-35	153	35	0,4	14,24 €
DBL880-25-40	153	40	0,4	14,24 €

Dimensions in mm

## Altri prodotti...



BSPT

Morsetto per guide,  
Rondo



CHMBR

Braccio di reazione,  
Braccio di reazione  
per riduttori CHM e  
CHMR



PDD

Pressore a molla  
sensore di  
rilevamento, Con asta  
di comando per int...



BZY\_55

Antivibrante elastico  
cilindrico inox, Inox



TBD

Tavola di  
posizionamento a  
passo inverso  
manuale, 40kg



AZY

Antivibrante elastico  
cilindrico, Acciaio



ZDB

Ingranaggio conico in  
plastica, 2:1



R204

Molla per stampi  
ISO10243, Medio



OP7

Indicatore di posizione  
digitale (N. di giri), 5  
cifre



PRF\_JL6

Panel accessories,  
Guarnizione - Ø 6mm



PW\_PWG25

Ruota di precisione,  
Bronzo



YG1

Ingranaggio dritto  
PRESTAZIONE, Acciaio  
35NCD6

## Prodotti correlati



CAP880

Catena a tapparella,  
Stretta serie 880



PR880

Ruota di rinvio, Serie  
880