



Socket with protective insert

Hygienic Design® and Usit®

DEP-HD

- Socket with protective plastic insert for mounting Hygienic Design® and Usit® products


- Materials:

Socket: tool steel

Insert: special PETP


Advantages

- 1/2" drive socket with a plastic insert to tighten and loosen screws and nuts in the Hygienic range. The plastic insert is made of special PETP and is FDA approved. The inserts are pressed into the socket by hand. Their special shape, combined with a clamping device, ensures optimal retention inside the socket.
- No special tools are required to replace worn plastic inserts.
- With a tightening torque (according to DIN standard for A4-70 screws and nuts, friction coefficient 0.12 μ) the inserts plastic have a life span of up to 1,000 cycles or more.

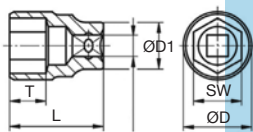

□12,5(1/2")

 DEP/HD socket



DEP/HD/INS insert

DISCOUNTS

Qty	1+	5+	10+
Disc	Net	-5%	On request

Part N°	ØD	ØD1	L	T	SW	SW1	Suitable for hexagonal screw	Price each
								1 to 4
Socket								
DEP-11/HD	16,6	22	37,3	10,1	11	-	-	25,65 €
DEP-13/HD	19,1	22	37,3	10,6	13	-	-	25,52 €
DEP-16/HD	22,9	23,6	37,1	11,3	16	-	-	26,87 €
DEP-19/HD	26,6	23	37,0	13,2	19	-	-	27,77 €
DEP-21/HD	29,0	25	36,8	12,9	21	-	-	43,21 €
DEP-27/HD	35,2	25	44,4	18,1	27	-	-	51,06 €
Protective insert								
DEP-8/HD/INS	-	-	18,0	6	11	8	M5	8,45 €
DEP-10/HD/INS	-	-	19,5	10	13	10	M6	8,52 €
DEP-13/HD/INS	-	-	21,5	11	16	13	M8	9,35 €
DEP-16/HD/INS	-	-	22,0	13,5	19	16	M10	9,82 €
DEP-18/HD/INS	-	-	21,5	12	21	18	M12	10,16 €
DEP-24/HD/INS	-	-	26,5	18	27	24	M16	14,51 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

61

Altri prodotti...



SSE

Snodo sferico inox,
Inox/PTFE



SH0

Ingranaggio elicoidale
ad assi paralleli,
Plastica lavorata
(delrin)



PAT85

Piede snodato con
base stampata Ø85, Ø
85



GB-RA

Ingranaggio dritto
ottone, Ottone
CuZn39Pb3



H02SS

Giunto cardanico
semplice ad aghi -
inox, Sollecitazioni
importante ...



CLB_M

Maniglia a ripresa,
Zamak



ATZY

Antivibrante elastico
sgolato, Acciaio



PRF_JL5

Panel accessories,
Guarnizione - Ø 5mm



PLM-SC

Magnete piatto, With
threaded hole



ACLBTS

Sistema di chiusura
per profili alluminio,
Spessore per blocca



CHAPAM

Cerniera a testa piatta
a saldare, Acciaio



PR40

Piede fissabile con
snodo - poliammide, Ø
40

Prodotti correlati