



Socket with protective insert

Hygienic Design® and Usit®

DEP-HD

- Socket with protective plastic insert for mounting Hygienic Design® and Usit® products


- Materials:

Socket: tool steel

Insert: special PETP


Advantages

- 1/2" drive socket with a plastic insert to tighten and loosen screws and nuts in the Hygienic range. The plastic insert is made of special PETP and is FDA approved. The inserts are pressed into the socket by hand. Their special shape, combined with a clamping device, ensures optimal retention inside the socket.
- No special tools are required to replace worn plastic inserts.
- With a tightening torque (according to DIN standard for A4-70 screws and nuts, friction coefficient 0.12 μ) the inserts plastic have a life span of up to 1,000 cycles or more.

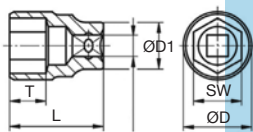

□12,5(1/2")

 DEP/HD socket



DEP/HD/INS insert

DISCOUNTS

| | | | |
|------|-----|-----|------------|
| Qty | 1+ | 5+ | 10+ |
| Disc | Net | -5% | On request |

| Part N° | ØD | ØD1 | L | T | SW | SW1 | Suitable for hexagonal screw | Price each |
|--------------------------|------|------|------|------|----|-----|------------------------------|------------|
| | | | | | | | | 1 to 4 |
| Socket | | | | | | | | |
| DEP-11/HD | 16,6 | 22 | 37,3 | 10,1 | 11 | - | - | 25,65 € |
| DEP-13/HD | 19,1 | 22 | 37,3 | 10,6 | 13 | - | - | 25,52 € |
| DEP-16/HD | 22,9 | 23,6 | 37,1 | 11,3 | 16 | - | - | 26,87 € |
| DEP-19/HD | 26,6 | 23 | 37,0 | 13,2 | 19 | - | - | 27,77 € |
| DEP-21/HD | 29,0 | 25 | 36,8 | 12,9 | 21 | - | - | 43,21 € |
| DEP-27/HD | 35,2 | 25 | 44,4 | 18,1 | 27 | - | - | 51,06 € |
| Protective insert | | | | | | | | |
| DEP-8/HD/INS | - | - | 18,0 | 6 | 11 | 8 | M5 | 8,45 € |
| DEP-10/HD/INS | - | - | 19,5 | 10 | 13 | 10 | M6 | 8,52 € |
| DEP-13/HD/INS | - | - | 21,5 | 11 | 16 | 13 | M8 | 9,35 € |
| DEP-16/HD/INS | - | - | 22,0 | 13,5 | 19 | 16 | M10 | 9,82 € |
| DEP-18/HD/INS | - | - | 21,5 | 12 | 21 | 18 | M12 | 10,16 € |
| DEP-24/HD/INS | - | - | 26,5 | 18 | 27 | 24 | M16 | 14,51 € |

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

61

Altri prodotti...



CHAM5270SS

Cerniera ad avvitare inox, Marine



KB_UU

Manicotto a sfere di precisione, Di precisione - acciaio



BGC

Giunto Oldham, con ganascia di serraggio



UTKpwc

Guida lineare Utilitrack®, Ruota a V - rivestimento polimero




T39_T49

Molla di trazione al metro inox, al metro



PF30NM

Riduttore a ruota e vite senza fine, fino a 8.8 Nm

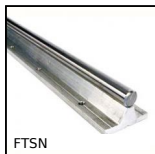


FTSN

Albero supportato per guida lineare, Albero acciaio / supporto allu...



MFB_MHB

Ingranaggio conico in plastica stampata, 4:1

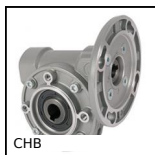


CHB

Riduttore a ruota e vite senza fine, fino a 22 Nm



SSB

Ingranaggio conico inox, 1:1

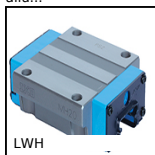

LWH

Guida lineare a sfere - Sfere acciaio, Carello - da 9320 N a 71300 N



PRF_PL_9090

Elementi di giunzione, Piastra di fissaggio - 90x90 mm

Prodotti correlati



EBC

Dado cieco Hygienic Design®, Compatto



VHTM

Hexagonal headed bolt Hygienic Design®, Inox