

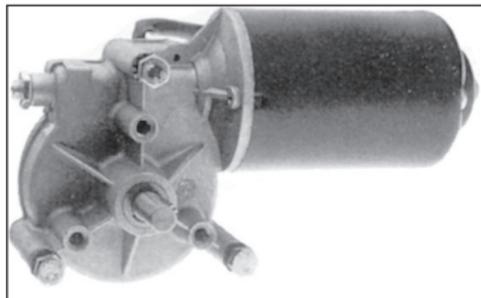


- Gearbox type: worm and wheel
- Bearing: self-lubricating bushes
- Angular backlash: N/A
- Max. axial load: N/A
- Max. radial load: N/A
- Working temp. from -40°C to +80°C
- Min. weight: 1.25kg
- Motor does not exhibit anti back drive behaviour for efficiencies less than 50%

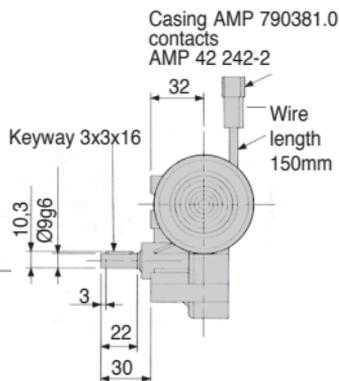

Accessories

- Servo Amplifier **FIRSTDC-1Q-60/10**
- Speed controller **NANODC-1Q-30/3**
- Power Supplies **ALIDR60-24, ALIDR120-24**

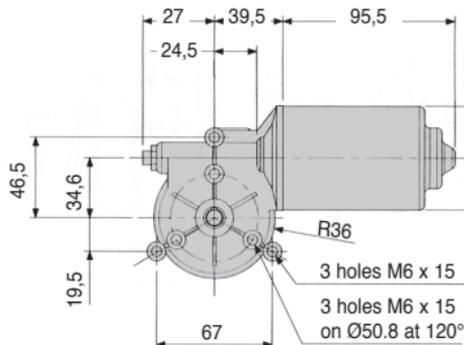

DISCOUNTS

Qty.	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	Efficiency (%)	Unloaded speed (rpm)	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (mA)	Price each 1 to 5
12 V DC Version							
DOG111-12-135	12,2:1	60	135	105	1,5	4,0	251,58 €
DOG111-12-50	62,0:1	45	50	40	5,0	5,0	135,44 €
DOG111-12-34	62,0:1	45	34	25	6,0	4,0	135,44 €
DOG111-12-17	62,0:1	45	17	10	6,0	2,0	138,23 €
24 V DC Version							
DOG111-24-270	12,2:1	60	270	240	1,5	4,0	251,58 €
DOG111-24-78	62,0:1	45	78	70	3,0	3,0	149,26 €
DOG111-24-50	62,0:1	45	50	40	5,0	2,5	143,73 €
DOG111-24-34	62,0:1	45	34	25	6,0	2,0	138,23 €

Dimensions in mm

Altri prodotti...



AT5courroie

Cinghia chiusa
posizionamento AT,
AT5 Poliuretano
armatura in acciaio



RFV40

Riduttore inox a ruota
e vite senza fine, fino
a 47 Nm



PSG05

Ingranaggio dritto di
precisione, Acciaio
20NCD2 cementato
temprato



T25-BAR

Barra dentata, T2.5



WJUM20

Pattino Drylin® W,
Pattino



GMK17_P

Guida prodotto
laterale piatta, Per
imbottigliamento e
imballaggio



NDS14C

Porta ventosa,
Connettore angolare
universale



BABreceptacle

Perno autobloccante,
Bussola di innesto



HG6-ECO

Ingranaggio dritto
acciaio - serie ECO,



G-ECO

Ingranaggio dritto
acciaio - serie ECO,



UGH16

Unità di guida tipo H,
Per martinetti Ø12 e



AT5P_AT10P

Piastra di giunzione
per cinghia AT, AT10

Prodotti correlati



NANO

Variatore di velocità
3A, 3 A



MDPOT

Potenzimetro,