

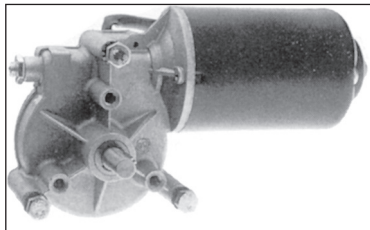


- Gearbox type: worm and wheel
- Bearing: self-lubricating bushes
- Angular backlash: N/A
- Max. axial load: N/A
- Max. radial load: N/A
- Working temp. from -40°C to +80°C
- Min. weight: 1.25kg
- Motor does not exhibit anti back drive behaviour for efficiencies less than 50%

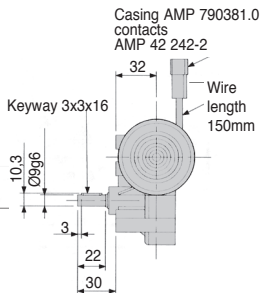

Accessories

- Servo Amplifier **FIRSTDC-1Q-60/10**
- Speed controller **NANODC-1Q-30/3**
- Power Supplies **ALIDR60-24, ALIDR120-24**

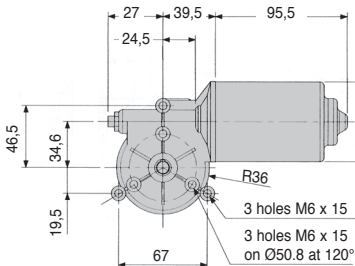

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty. | 1+ | 6+ | 10+ |
| Disc. | List | -7% | On request |

| Part number | Ratios | Efficiency (%) | Unloaded speed (rpm) | Loaded speed (rpm) | Nominal torque (Nm) | Nominal current (mA) | Price each 1 to 5 |
|------------------------|--------|----------------|----------------------|--------------------|---------------------|----------------------|-------------------|
| 12 V DC Version | | | | | | | |
| DOG111-12-135 | 12,2:1 | 60 | 135 | 105 | 1,5 | 4,0 | 251,58 € |
| DOG111-12-50 | 62,0:1 | 45 | 50 | 40 | 5,0 | 5,0 | 135,44 € |
| DOG111-12-34 | 62,0:1 | 45 | 34 | 25 | 6,0 | 4,0 | 135,44 € |
| DOG111-12-17 | 62,0:1 | 45 | 17 | 10 | 6,0 | 2,0 | 138,23 € |
| 24 V DC Version | | | | | | | |
| DOG111-24-270 | 12,2:1 | 60 | 270 | 240 | 1,5 | 4,0 | 251,58 € |
| DOG111-24-78 | 62,0:1 | 45 | 78 | 70 | 3,0 | 3,0 | 149,26 € |
| DOG111-24-50 | 62,0:1 | 45 | 50 | 40 | 5,0 | 2,5 | 143,73 € |
| DOG111-24-34 | 62,0:1 | 45 | 34 | 25 | 6,0 | 2,0 | 138,23 € |

Dimensions in mm


Altri prodotti...



CHTRP
Riduttore a rinvio
angolare a L o a T,
fino a 87,3Nm



HG5-ECO
Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45

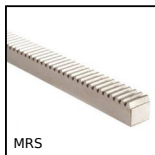

MRS
Cremagliera sezione
metrica, Inox



RBS
Rondella elastica ,
Acciaio



MC
Deceleratore,
autoregolante -
senza regolazione



CHTRB
Riduttore a rinvio
angolare a L o a T,
fino a 87,3 Nm



PP50
Riduttore a ruota e
vite senza fine, da
6.50 a 12.80 Nm



SFE
Testa a snodo
femmina, Inox / PTFE



PSG2
Ingranaggio dritto di
precisione, Acciaio
35NCD6 pretrattato



SHN
Dado esagonale -
DIN934, Acciaio (Class
6[8])



ACM_TRI
Tirante chiusura in
gomma, Caucciù




VBFP
Volantino a 6 lobi -
boccola passante,
Duroplast - Inox

Prodotti correlati



FIRSTDC1Q60
Variatore di velocità
10A, 10 A

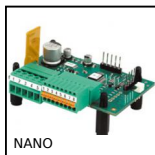

NANO
Variatore di velocità
3A, 3 A



MDPOT
Potenziometro,