



Motor-gearbox 12V and 24V DC



Torque from 12Nm to 15Nm

DOG258

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Angular backlash: N/A
- Max. axial load: N/A
- Max. radial load: N/A
- Working temp.: -40°C to +80°C
- Weight: 3kg
- Ingress protection: IP53

Accessories

- Speed controller not available
- Servo amplifier **FIRSTDC -1Q-60/10**
- Power Supplies **ALIDR120-14,ALIDRP240-24**
- **HPC is unable to supply a speed controller for this motor gearbox**
- **The encoder cannot be mounted behind the motor.**

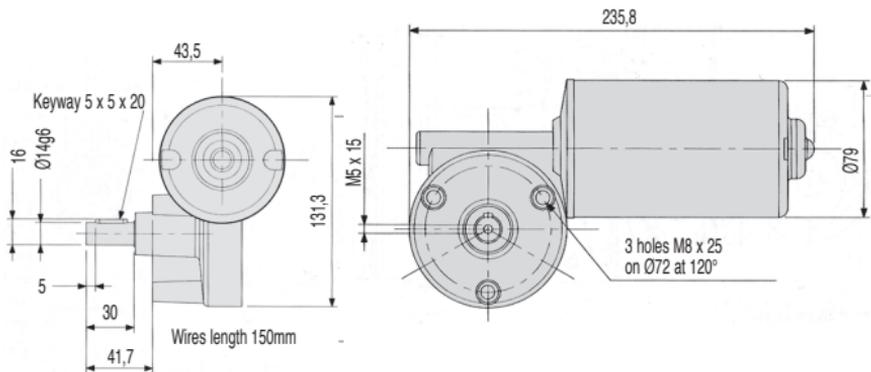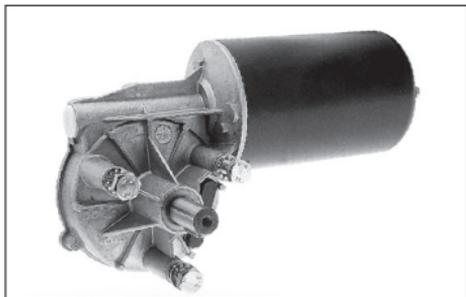

DISCOUNTS

Qty.	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	Unloaded speed (rpm)	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (mA)	Price each 1 to 5
12 V DC Version						
DOG258-12-50	52:1	50	40	12	12	403,65 €
DOG258-12-30	52:1	30	25	15	10	403,65 €
24 V DC Version						
DOG258-24-50	52:1	50	40	12	6	403,65 €
DOG258-24-30	52:1	30	25	15	5	403,65 €

Dimensions in mm

Altri prodotti...



KON

Piedino antivibrante cilindrico, Inox



LVT

Mini martinetto motorizzato 4A, 4 ampere



BOX-WM

Rondella semplice - DIN125, Valigetta di rondelle acciaio



MCL

Manicotto cilindrico maschiato, Cilindrico - inox



F7-SF-SM

Visualizzatore multifunzione, Supporto - montaggio ortogonale



BAC105

Contenitore a becco, 8mm



TS01_TW01

Guida lineare su binario Drylin® T, fino al 7000 N



UCP

Cuscinetto ritto in ghisa, Ghisa



TB_ECO

Ingranaggio conico - Acciaio C43 - ECO, 3:1



UTKswrr

Guida lineare Utilitrack®, Profilo



J51

Riduttore coassiale a treni paralleli, da 0.13



LACT_SS

Leva a camma regolabile, Maschio

Prodotti correlati



ALIDRP240

Alimentazione, 10 A



MDPOT

Potenziometro,