


Motor-gearbox 12V and 24V DC

DOG316



Torque from 1.5Nm to 2Nm

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Working temp.: -40°C to +80°C
- Weight: 1kg
- Ingress protection: IP40
- Angular backlash: N/A
- Max axial load: N/A
- Radial load: N/A

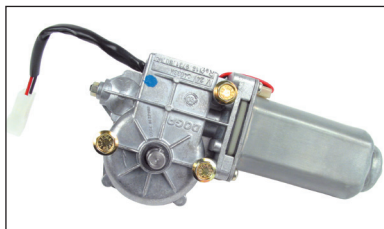

Accessories

- Servo Amplifiers **FIRSTDC-1Q-60/10** and **NANODC-1Q-30/3**
- Power Supplies **ALIDR30-12**, **ALIDR60-24**, **ALIDR-120-24**

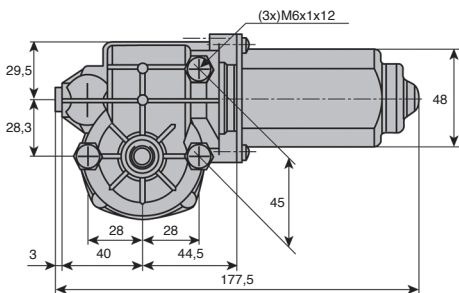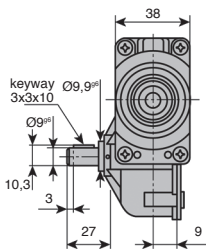

DISCOUNTS

Qty.	1+	6+	10+
Disc. List	-7%	On request	

Part number	Ratios	Efficiency	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each 1 to 5
12V DC Version						
DOG316-12-46	62:1	0,5	38	2,0	3,4	116,08 €
DOG316-12-30	62:1	0,5	32	1,5	3,0	116,08 €
24V DC Version						
DOG316-24-75	62:1	0,5	65	1,5	3,0	116,08 €
DOG316-24-46	62:1	0,5	38	2,0	1,7	116,08 €

Dimensions in mm

Altri prodotti...



M1

Coppia ruota e vite senza fine, Bronzo



DIA

Pistoncino a molla, con anello



LVT

Mini martinetto motorizzato 1A, 1 ampere



SH0

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2




CLSCLP_SS

Forcella e perno serie Corta, Corta inox



KGS

Vite a ricircolo di sfere al metro, Vite a sfere rullata, al metro

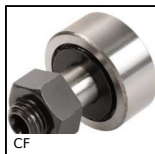

CF

Perno folle, Standard - acciaio



VPSS

Volantino a 6 lobi, Duroplast - Inox



SLB

Pistoncino a molla, inox



PSPT

Manopola a pressione, PVC



FBL6000_K19

Spazzola al metro, Crine di cavallo nero



VTLF

Volantino a 3 lobi, Poliammide - Ottone

Prodotti correlati



ALIDRP240

Alimentazione, 10 A



NANO

Variatore di velocità 3A, 3 A



FIRSTDC1Q60

Variatore di velocità 10A, 10 A



MDPOT

Potenziometro, 10A, 10 A