

Motor-gearbox 12V and 24V DC

DOG316



Torque from 1.5Nm to 2Nm

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Working temp.: -40°C to +80°C
- Weight: 1kg
- Ingress protection: IP40
- Angular backlash: N/A
- Max axial load: N/A
- Radial load: N/A



Accessories

- Servo Amplifiers **FIRSTDC-1Q-60/10** and **NANODC-1Q-30/3**
- Power Supplies **ALIDR30-12**, **ALIDR60-24**, **ALIDR-120-24**

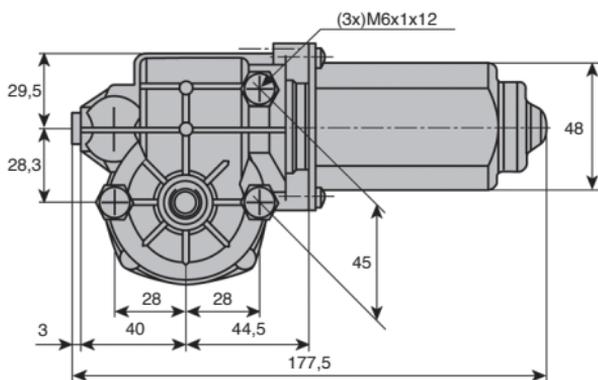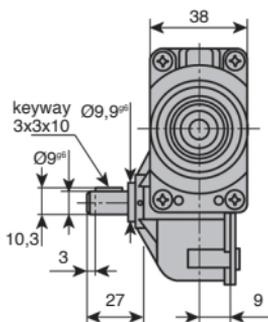

DISCOUNTS

Qty.	1+	6+	10+
Disc. List		-7%	On request

Part number	Ratios	Efficiency	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each 1 to 5
12V DC Version						
DOG316-12-46	62:1	0,5	38	2,0	3,4	116,08 €
DOG316-12-30	62:1	0,5	32	1,5	3,0	116,08 €
24V DC Version						
DOG316-24-75	62:1	0,5	65	1,5	3,0	116,08 €
DOG316-24-46	62:1	0,5	38	2,0	1,7	116,08 €

Dimensions in mm

Altri prodotti...



MEB

Ingranaggio conico in
plastica stampata, 1:1



NDS14C

Porta ventosa,
Connettore angolare
universale



ZY

Piedino antivibrante
cilindrico, Inox



ACLBTS

Sistema di chiusura,
Blocca porta a sfera



ES

Bipod support base,
Plastic



RT70

Calettatore di
bloccaggio, Coppia
media/elevata




ZB

Albero per guida
lineare, Inox temprato




PARF80

Piede senza snodo,
Piede snodato
oscillante fissabile
Ø80

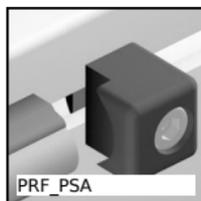

PRF_PSA

Rotella per profilo
alluminio, per
bloccaggio albero

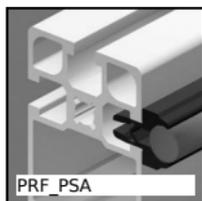

PRF_PSA

Rotella per profilo
alluminio, Supporto
d'albero



BTE

Tenditore automatico
universale, Per
applicazioni correnti



HK

Accessorio di
serraggio manuale,
Serraggio manuale
LWL

Prodotti correlati



ALIDR30

Alimentazione, 1,5 A
and 2 A



NANO

Variatore di velocità
3A, 3 A