


Motor-gearbox 12V and 24V DC



DOG319



Torque from 4Nm to 9Nm

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Angular backlash: N/A
- Max. axial load: N/A
- Max. radial load: N/A
- Working temperature: -40°C to +80°C
- Weight 1.7kg
- Materials:
 - Screws: steel
- Wheel: POM

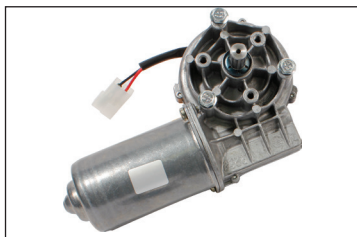

Accessories

- Servo Amplifier **FIRSTDC-1Q-60/10**
- Speed controller **NANODC-1Q-30/3**
- Power Supplies **ALIDR120-24, ALIDR240-24**

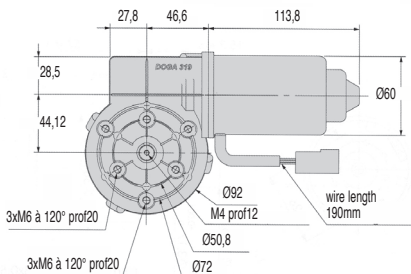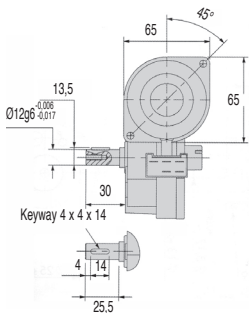

DISCOUNTS

Qty.	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	No-load speed (rpm)	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (mA)	Price each 1 to 5
12 V DC Version						
DOG319-12-15	81:1	18	15	9	3	214,91 €
DOG319-12-30	81:1	35	30	9	7	215,52 €
DOG319-12-45	81:1	50	45	8	6	214,91 €
DOG319-12-85	39:1	95	85	4	7	263,16 €
24 V DC Version						
DOG319-24-30	81:1	30	30	9	3	227,63 €
DOG319-24-45	81:1	45	45	9	3	203,94 €
DOG319-24-85	39:1	95	85	4	3,5	271,93 €

Dimensions in mm

Altri prodotti...



RPCtcss

Ruota girevole a foro centrale, Inox - Poliammide - a doppio bloccag...




NSO

Supporto standard per manicotto aperto a sfere, Aperto - lungo



HLC24

Rinvio angolare a dentatura spiroidale, Fino a 78Nm

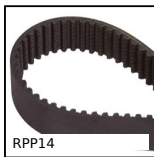

RPP14

Cinghia di trasmissione RPP, RPP14



BLHB40

Rinvio angolare ad albero cavo, fino a 10.3 Nm



CMAss

Vite ad occhio, Inox



CAP881

Catena a tapparella, Stretta serie 881



ADL_F

Anello di sollevamento, Acciaio




CHA_GC_9SS

Cerniera (tutto inox), A saldare



LPCM

Leva con impugnatura cilindrica, Duroplast nero, leva in acciaio

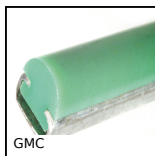

GMC


Guida prodotto laterale tonda, Per imbottigliamento e imballaggio



T10courroie

Cinghia di posizionamento T, T10 Poliuretano armatura in acciaio

Prodotti correlati

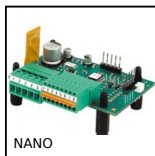

NANO

Variatore di velocità 3A, 3 A



MDPOT

Potenzimetro,