


# Motor-gearbox 12V and 24V DC



## DOG319



## Torque from 4Nm to 9Nm

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Angular backlash: N/A
- Max. axial load: N/A
- Max. radial load: N/A
- Working temperature: -40°C to +80°C
- Weight 1.7kg
- Materials:
  - Screws: steel
- Wheel: POM

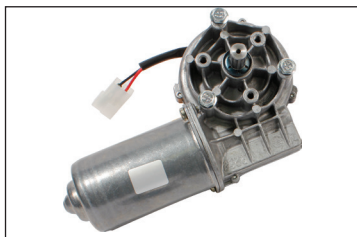

### Accessories

- Servo Amplifier **FIRSTDC-1Q-60/10**
- Speed controller **NANODC-1Q-30/3**
- Power Supplies **ALIDR120-24, ALIDR240-24**

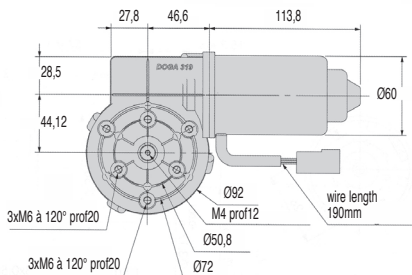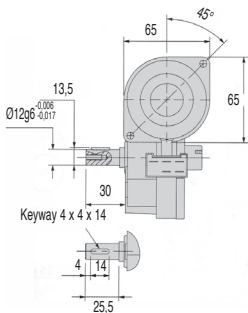

### DISCOUNTS

Qty.	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	No-load speed (rpm)	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (mA)	Price each 1 to 5
<b>12 V DC Version</b>						
DOG319-12-15	81:1	18	15	9	3	214,91 €
DOG319-12-30	81:1	35	30	9	7	215,52 €
DOG319-12-45	81:1	50	45	8	6	214,91 €
DOG319-12-85	39:1	95	85	4	7	263,16 €
<b>24 V DC Version</b>						
DOG319-24-30	81:1	30	30	9	3	227,63 €
DOG319-24-45	81:1	45	45	9	3	203,94 €
DOG319-24-85	39:1	95	85	4	3,5	271,93 €

Dimensions in mm

## Altri prodotti...



LFM

Vite trapezoidale  
acciaio, Acciaio  
semiduro - 1 filetto



QN

Cuscinetto a singola  
corona di rulli  
cilindrici, Anello  
esterno libero



PRF\_PL\_4590

Elementi di giunzione,  
Piastra di giunzione -  
45x90 mm



GCL

Guida lineare a sfere -  
Sfere inox, Carello -  
da 516 N a 8396 N



DB

Ingranaggio conico in  
acciaio, 2:1



PPD

Pistoncino a molla,  
Per lamiera



AKD

Giunto a soffietto  
Gerwah®, da 22 a  
600Nm



PRF\_PGN

Maniglia e battuta per  
porta, Maniglia con  
serratura




GPBSS

Impugnatura sferica  
femmina filettata,



COA-COG

Staffa di montaggio  
per molla a gas,

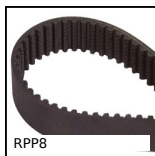

RPP8

Cinghia di  
trasmissione RPP,



T5P\_T10P

Piastra di giunzione  
per cinghia T, T5

## Prodotti correlati



FIRSTDC1Q60

Variatore di velocità  
10A, 10 A



ALIDR30

Alimentazione, 1,5 A  
and 2 A



MDPOT

Potenzimetro,