


Chain idler sprocket

New

DTR


Steel or plastic

- **Disk shaped idler sprocket**
- Bearing incorporated
- Lubricated for life
- **Materials:**
 - Sprocket in XC38 zinc plated steel or PA6 polyamide (30% glass fibre)
 - Steel bearing
- Max speed 70m/min
- Working temp -30/+80°C

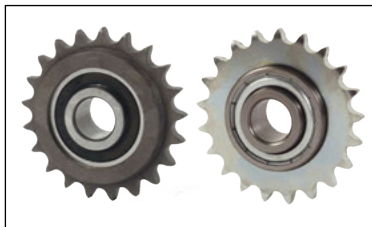

Info

- For use with **SBR** chains

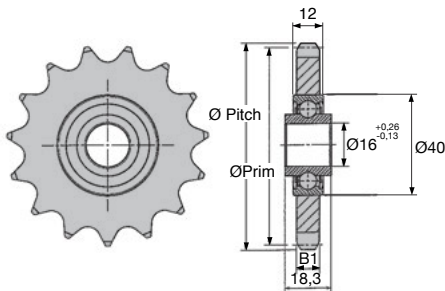

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	Pitch	Standard	N° of teeth	ØPitch	ØPrim	B1	Bearing	Unit price 1 to 9
Steel								
DTR-06B1-21	9,525	06B1	21	68,00	63,90	5,30	203KRR	11,48 €
DTR-08B1-16	12,7	08B1	16	69,50	65,10	7,20	203KRR	12,12 €
DTR-10B1-15	15,875	10B1	15	83,00	76,36	9,10	203KRR	14,40 €
DTR-12B1-13	19,05	12B1	13	87,50	79,59	11,10	203KRR	15,63 €
DTR-12B1-15	19,05	12B1	15	99,80	91,63	11,10	203KRR	16,96 €
Plastic								
DTR-06B1-21/Z	9,525	06B1	21	68,00	63,90	5,30	203KRR	17,54 €
DTR-08B1-16/Z	12,7	08B1	16	69,50	65,10	7,20	203KRR	18,24 €
DTR-10B1-15/Z	15,875	10B1	15	83,00	76,36	9,10	203KRR	19,19 €
DTR-12B1-13/Z	19,05	12B1	13	87,50	79,59	11,10	203KRR	20,91 €
DTR-12B1-15/Z	19,05	12B1	15	99,80	91,63	11,10	203KRR	22,55 €

Dimensions in mm

Altri prodotti...



HTD5M_09

Puleggia dentata di trasmissione tipo HTD, HTD5 Acciaio



UFX

Giunto elastico Uniflex®, economica



EKGS

Giunto senza gioco Gerwah®, da 0.5 a 35Nm



CABma

Manicotto ovale per cavo, Per la crimpatura di un cavo in acciaio



LVT

Mini martinetto motorizzato 4A, 4 ampere



AT10courroie

Cinghia di posizionamento AT, AT10 Poliuretano armatura in acciaio



Q6

Cuscinetto radiale a sfere, Acciaio



GP75

Chiusura a leva molla a trazione compensata, Standard (GP75)



RFVbr

Riduttore inox a ruota e vite senza fine, Braccio di reazione



DSF

Limitatore di coppia a scivolamento, 4 a 2800 Nm



ZBconique

Ingranaggio conico in plastica, 1:1



CM_CO

Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...

Prodotti correlati



SUA4

Catena semplice al metro, Acciaio