

Chain idler sprocket

New

DTR


Steel or plastic

- **Disk shaped idler sprocket**
- Bearing incorporated
- Lubricated for life
- **Materials:**
 - Sprocket in XC38 zinc plated steel or PA6 polyamide (30% glass fibre)
 - Steel bearing
- Max speed 70m/min
- Working temp -30/+80°C



Info

- For use with **SBR** chains

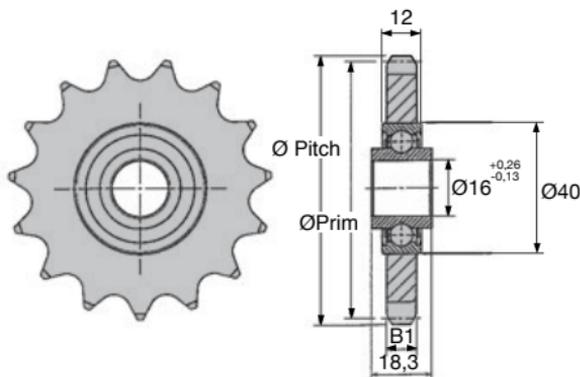

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	


Part number	Pitch	Standard	N° of teeth	ØPitch	ØPrim	B1	Bearing	Unit price 1 to 9
Steel								
DTR-06B1-21	9,525	06B1	21	68,00	63,90	5,30	203KRR	11,48 €
DTR-08B1-16	12,7	08B1	16	69,50	65,10	7,20	203KRR	12,12 €
DTR-10B1-15	15,875	10B1	15	83,00	76,36	9,10	203KRR	14,40 €
DTR-12B1-13	19,05	12B1	13	87,50	79,59	11,10	203KRR	15,63 €
DTR-12B1-15	19,05	12B1	15	99,80	91,63	11,10	203KRR	16,96 €
Plastic								
DTR-06B1-21/Z	9,525	06B1	21	68,00	63,90	5,30	203KRR	17,54 €
DTR-08B1-16/Z	12,7	08B1	16	69,50	65,10	7,20	203KRR	18,24 €
DTR-10B1-15/Z	15,875	10B1	15	83,00	76,36	9,10	203KRR	19,19 €
DTR-12B1-13/Z	19,05	12B1	13	87,50	79,59	11,10	203KRR	20,91 €
DTR-12B1-15/Z	19,05	12B1	15	99,80	91,63	11,10	203KRR	22,55 €

Dimensions in mm

Altri prodotti...



PSG125S
Ingranaggio dritto di
precisione, Inox 303

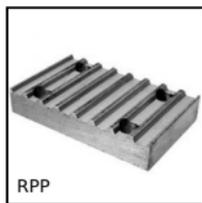

RPP
Piastra di giunzione
per cinghia RPP, RPP5



CHB
Single output shaft,
For CHB gearbox



JCSs
Giunto cardanico -
inox, Sollecitazioni
leggere



PSG08S
Ingranaggio dritto di
precisione, Inox 316



GPLny
Scovolo, nylon



PITA
Pistoncino a molla,
con maniglia a T



RJUM01
Manicotto a sfere,
Drylin® R



BOXdhx
Box kit di spine
filettate DIN7979D,
Box kit - estraibile DIN



PR65C
Half-articulated foot \varnothing
65, \varnothing 65



BHC
Vite a testa bombata
BHC , Inox A2



CHTRP
Riduttore a rinvio
angolare a L o a T,
fino a 9,1 Nm

Prodotti correlati



SUA4
Catena semplice al
metro, Acciaio