


Chain idler sprocket

New

DTR


Steel or plastic

- **Disk shaped idler sprocket**
- Bearing incorporated
- Lubricated for life
- **Materials:**
 - Sprocket in XC38 zinc plated steel or PA6 polyamide (30% glass fibre)
 - Steel bearing
- Max speed 70m/min
- Working temp -30/+80°C

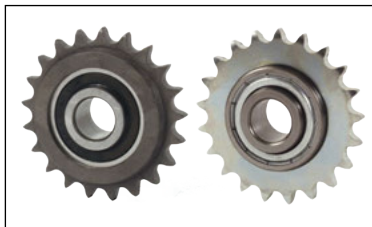

Info

- For use with **SBR** chains

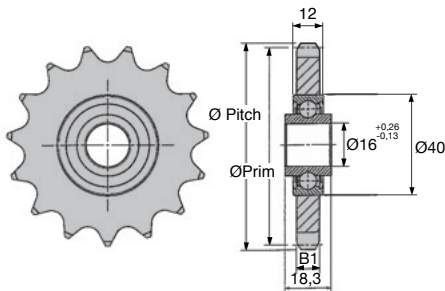

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	Pitch	Standard	N° of teeth	ØPitch	ØPrim	B1	Bearing	Unit price 1 to 9
Steel								
DTR-06B1-21	9,525	06B1	21	68,00	63,90	5,30	203KRR	11,48 €
DTR-08B1-16	12,7	08B1	16	69,50	65,10	7,20	203KRR	12,12 €
DTR-10B1-15	15,875	10B1	15	83,00	76,36	9,10	203KRR	14,40 €
DTR-12B1-13	19,05	12B1	13	87,50	79,59	11,10	203KRR	15,63 €
DTR-12B1-15	19,05	12B1	15	99,80	91,63	11,10	203KRR	16,96 €
Plastic								
DTR-06B1-21/Z	9,525	06B1	21	68,00	63,90	5,30	203KRR	17,54 €
DTR-08B1-16/Z	12,7	08B1	16	69,50	65,10	7,20	203KRR	18,24 €
DTR-10B1-15/Z	15,875	10B1	15	83,00	76,36	9,10	203KRR	19,19 €
DTR-12B1-13/Z	19,05	12B1	13	87,50	79,59	11,10	203KRR	20,91 €
DTR-12B1-15/Z	19,05	12B1	15	99,80	91,63	11,10	203KRR	22,55 €

Dimensions in mm

Altri prodotti...



DOMI50

Slitta di regolazione
Domino 50, Slitta
DOMILINE 50



CHAE4060PA

Cerniera ad avvitare
estetica asimmetrica,
Poliammide



ZBconique

Ingranaggio conico in
plastica, 1:1



CHA38_SS

Cerniera su facciata
ad avvitare inox, Su
facciata



PRF-SCL

Sistema di chiusura
per profili alluminio,
Lock for sliding doors



HS

Distanziatore
esagonale, Inox 303



CNA-CNG

Staffa di montaggio
per molla a gas,
Staffa di montaggio a
squadra p...



CHMR110

Riduttore a ruota e
vite senza fine, fino a
980 Nm




RBS

Rondella elastica ,
Acciaio




M1

Coppia ruota e vite
senza fine , Acciaio

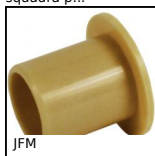

JFM

Cuscinetto a collare ,
Polimero universale

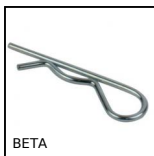

BETA

Copiglia beta, Beta

Prodotti correlati



SUA4

Catena semplice al
metro, Acciaio