

- Compact cap nut



- Material:

Stainless steel 1.4404 (316L)

Polished finish

Advantages

- The surface of the cap nut is polished and is specially shaped for use in hygienic environments
- The head of the nut is hemispherical and the collar has a conical top face
- The overall height has been kept deliberately low to reduce any inconvenient edges to a minimum.

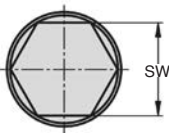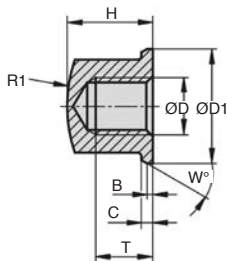

DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc	Net	-5%	-10%	-15%	On request

Part N°	ØD	ØD1	B	C	H	R1	SW	T	W	Price each
										1 to 4
EBC-3/HDSS	M3	6,8	0,25	0,5	4,95	8,8	5,5	3	20	3,40 €
EBC-4/HDSS	M4	9	0,30	0,8	6,5	10	7	4	30	3,43 €
EBC-5/HDSS	M5	10	0,50	1,0	7	16	8	4	30	3,61 €
EBC-6/HDSS	M6	12	0,80	1,0	9	16	10	6	30	4,41 €
EBC-8/HDSS	M8	16	0,80	1,6	12	20	13	8	30	4,56 €
EBC-10/HDSS	M10	20	1,00	2,0	14	32	16	10	30	5,48 €
EBC-12/HDSS	M12	24	1,00	2,5	16	35	19	11	30	10,63 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Altri prodotti...



CNA-CNG

Staffa di montaggio per molla a gas, Staffa di montaggio a squadra p...



ACM_AZ

Aggancio per tirante chiusura in gomma, Aggancio



F7-SF-SM

Visualizzatore multifunzione, Supporto - montaggio ortogonale



STC

Deceleratore, Ghiera d'arresto



BPHF

Sfera portante, Forte



MDB_MTB

Ingranaggio conico in plastica stampata, 3:1



SUPCC

Calettatore di bloccaggio autocentrante acciaio, Con ghiera




NDS20

Connettore di serraggio, Incrociata



BPPL

Attrezzo di montaggio per sfera portante,

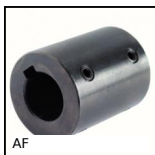

AF

Giunto rigido con cava chiavetta, Set screw



VB

Volantino a 6 lobi, Duroplast - Ottone



PW_PWG1

Ruota di precisione, Bronzo

Prodotti correlati



DEP

Attrezzi Hygienic Usit® and Hygienic Design®, Bussole per il monta...