

- Compact cap nut



- Material:

Stainless steel 1.4404 (316L)

Polished finish

Advantages

- The surface of the cap nut is polished and is specially shaped for use in hygienic environments
- The head of the nut is hemispherical and the collar has a conical top face
- The overall height has been kept deliberately low to reduce any inconvenient edges to a minimum.

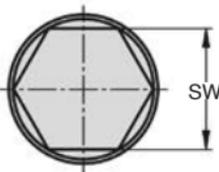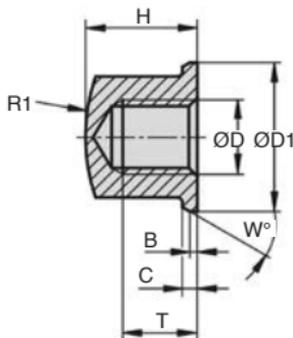

DISCOUNTS


Qty	1+	5+	10+	25+	50+
Disc	Net	-5%	-10%	-15%	On request

Part N°	ØD	ØD1	B	C	H	R1	SW	T	W	Price each
										1 to 4
EBC-3/HDSS	M3	6,8	0,25	0,5	4,95	8,8	5,5	3	20	3,40 €
EBC-4/HDSS	M4	9	0,30	0,8	6,5	10	7	4	30	3,43 €
EBC-5/HDSS	M5	10	0,50	1,0	7	16	8	4	30	3,61 €
EBC-6/HDSS	M6	12	0,80	1,0	9	16	10	6	30	4,41 €
EBC-8/HDSS	M8	16	0,80	1,6	12	20	13	8	30	4,56 €
EBC-10/HDSS	M10	20	1,00	2,0	14	32	16	10	30	5,48 €
EBC-12/HDSS	M12	24	1,00	2,5	16	35	19	11	30	10,63 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Altri prodotti...

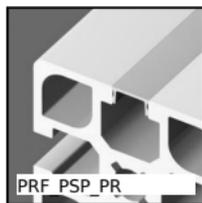

PRF_PSP_PR
Profilato di copertura,
Da inserire nelle
scalature



NJM
Connettore rinvio
d'angolo, Multiplo



SH2
Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2



BAP
Anello di bloccaggio,
Ø10 - Ø20



R204
Molla per stampi
ISO10243, Medio



PRF_BP
Maniglia e battuta per
porta, Arresto per
porta a battente



TBEBASE10
Economic mini-table
with trapezoidal
leadscrew, Economica



RCX-6
Rondella sferica -
DIN6319, concava



BIM
Pistoncino a molla,
miniatura



KBS_UU
Manicotto chiuso a
sfere inox di
precisione, Di



BOX-TOR-G
Valigetta di
guarnizioni toriche in
nitrile, 3.00 x 1.50mm



BPHT
Sfera portante
fissaggio con perno
filettato, Forte

Prodotti correlati



DEP
Attrezzi Hygienic
Usit® and Hygienic
Design®, Bussole per
il monta...