
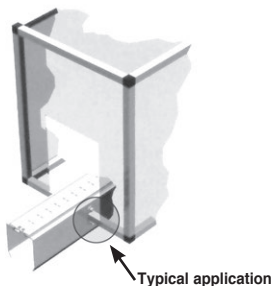


- Support for square section tube
- Material: stainless steel 304

Accessories

- Connecting joint NCT
- Tube TUBE25-25

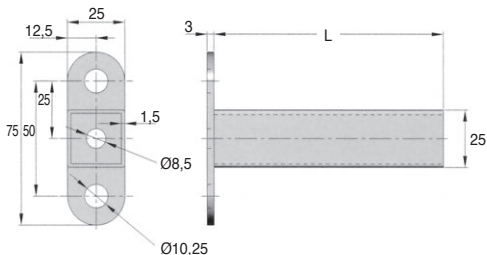

DISCOUNTS

Qty.	1+	10+	21+
Disc.	List -5%	On request	

Part number	L	Weight (kg)	Stock*	Price each 1 to 9
EFTC25-50/SS	50	0,09	✓	9,26 €
EFTC25-100/SS	100	0,15	✓	10,01 €
EFTC25-150/SS	150	0,20	✓	10,90 €

*Depending on availability - Dimensions in mm

Altri prodotti...



J51

Riduttore coassiale a treni paralleli, da 0.13 a 0.49 - a treni para...



CHMR63

Riduttore a ruota e vite senza fine, fino a 196 Nm



DER63

Motore inox AC asincrono 0,18kW, 0,18kW



BAGO

Anello di bloccaggio, Inox



BPLE

Sfera portante a incastro, Leggero



SER69K-CLE

Chiusura 1/4 di giro per agroalimentare, Chiave



EHD06

Riduttore coassiale, da 8 a 19 Nm



CDGamme

Molla di compressione DIN2095, DIN 2095



IN1

Ingranaggio interno, Acciaio 20NCD2



HG6-ECO

Ingranaggio dritto acciaio - serie ECO,



PLC_PLT

Magnete, Con foro centrale



TCC

Tenditore, Acciaio

Prodotti correlati



TUBE25_25

Tubo quadrato, Alluminio