

Tee nuts with pronge

EGRM

Steel


- Socket nut that easily inserts into soft materials
- Remains in place without turning
- Material :
Steel zinc plated

Advantages

- Tee nuts with pronge increase clamping quality in soft materials (wood, panels, chipboard, plastics)
- Repeated tightening without damaging the surface

Info

- Sold by the packet

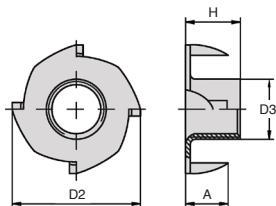

DISCOUNTS

| | | | |
|-------|------|------|------------|
| Qty | 1+ | 6+ | 10+ |
| Disc. | List | -10% | On request |

| Part number | Thread ØM | ØD2 | ØD3 | H | A | Qty per packet | Price per packet |
|-------------|--------------|-----|------|----|----|-------------------|---------------------|
| EGRM4-6/B | M4 | 15 | 5 | 6 | 5 | 200 | |
| EGRM5-8/B | M5 | 17 | 6,5 | 8 | 7 | 200 | |
| EGRM6-9/B | M6 | 19 | 7,5 | 9 | 7 | 200 | |
| EGRM6-12/B | M6 | 19 | 7,5 | 12 | 8 | 200 | |
| EGRM8-11/B | M8 | 22 | 10 | 11 | 9 | 100 | |
| EGRM8-15/B | M8 | 22 | 10 | 15 | 10 | 100 | |
| EGRM10-13/B | M10 | 25 | 11,5 | 13 | 11 | 100 | |

Dimensions in mm

Altri prodotti...



CHMR110

Riduttore a ruota e vite senza fine, fino a 980 Nm



PLM-SC

Magnete piatto con foro svasato, Con foro fresato



JCDss

Giunto cardanico - inox, Sollecitazioni leggere



SLB

Pistoncino a molla, inox



T25-BAR

Barra dentata, T2.5



KGS

Vite a ricircolo di sfere al metro, Vite a sfere rullata, al metro



H4

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



SLH

Attrezzo di bloccaggio a leva orizzontale, A leva orizzontale - acci...



CHAEss

Cerniera estetica, Inox



PW_PWG1

Vite senza fine di precisione, Acciaio



DCA

Ventosa, silicone



BH01

Cuscinetto radiale flangiato, Montaggio : pressione e colla

Prodotti correlati