

Antistatic knurled nut

EMAS Prevents occurrence of electrostatic spark

Eliminates electrical charges

- Materials :

Reinforced PA thermoplastic, graphite black
Tapped bush in steel trivalent blue passivated

Advantages



- These products can be used for electrostatic discharge applications or areas where electrostatic discharge protection (EPA) in accordance with DIN EN61340-5-1
- The knurled nuts can be tightened or loosened without tools



NEW!



Antistatic

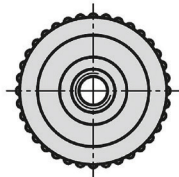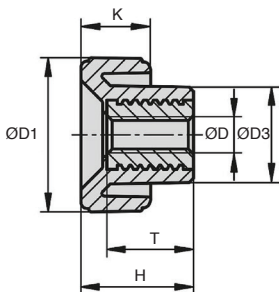

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	ØD1	ØD3	H	K	T	Price each
							1 to 9
EMAS18-M4	M4	18	11	13	8	10	6,12 €
EMAS20-M5	M5	20	13,6	15	9	10	6,61 €
EMAS25-M6	M6	25	14	17	10	10	7,24 €
EMAS32-M8	M8	32	18	22	13	14	8,30 €
EMAS40-M10	M10	40	19	25	14	14	9,03 €

Dimensions in mm

Altri prodotti...



GLT3E-58

Guide telescopiche acciaio, Estensione extra



GCL

Guida lineare a sfere - Sfere inox, Carello - da 516 N a 8396 N



G-ECO

Ingranaggio dritto acciaio - serie ECO, Acciaio C45



NT121

Riduttore coassiale a treni paralleli, da 20 a 68 Nm - a treni paral...




RPP

Piastra di giunzione per cinghia RPP, RPP5



M0

Vite senza fine, Acciaio non temprato

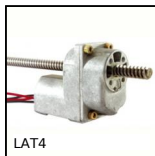

LAT4

Attuatore lineare a motore 4A, 4 ampere



ACLERP

Rulliera, Senza guida laterale



PRF_BASE

Elementi di ancoraggio,



SSDB

Ingranaggio conico inox, 2:1



PR40

Piede fissabile con snodo - poliammide, Ø



T25-BAR

Barra dentata, T2.5

Prodotti correlati



BEAS

Star shaped anti-static handle, Star, anti-static



PAS

Maniglia a ponte, Reinforced PA thermoplastic



BEAS

Manopola, stella, antistatico