

Antistatic knurled nut

EMAS Prevents occurrence of electrostatic spark

Eliminates electrical charges

- Materials :

Reinforced PA thermoplastic, graphite black
Tapped bush in steel trivalent blue passivated

Advantages



- These products can be used for electrostatic discharge applications or areas where electrostatic discharge protection (EPA) in accordance with DIN EN61340-5-1
- The knurled nuts can be tightened or loosened without tools



NEW!



Antistatic

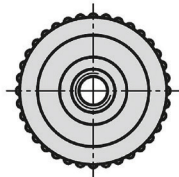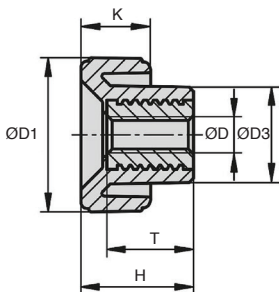

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	ØD1	ØD3	H	K	T	Price each
							1 to 9
EMAS18-M4	M4	18	11	13	8	10	6,12 €
EMAS20-M5	M5	20	13,6	15	9	10	6,61 €
EMAS25-M6	M6	25	14	17	10	10	7,24 €
EMAS32-M8	M8	32	18	22	13	14	8,30 €
EMAS40-M10	M10	40	19	25	14	14	9,03 €

Dimensions in mm

Altri prodotti...



PDM_PDV

, by metal detectors




RURp

Rotella girevole con piastra, Poliuretano - Mozzo alluminio (Ultra S...



BLHT70

Rinvio angolare a T, da 26 a 128 Nm

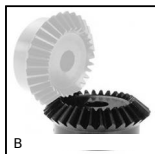

B

Ingranaggio conico - Acciaio 60C40, 1:1



LF

Cuscinetti a sfere - Accessorio, Ghiera di regolazione



MRASeco

Maglia rapida economica, Inox



LRR

Chiavistello con perno prismatico, Gancio



VML

Volantino a lobi, Vite di pressione



BVR

Battute a vite regolabile, Acciaio




DOG316

Motoriduttore DC 12V e 24V DC, da 1.5 a 2



STRIP

Spazzola strip, Lunghezza 1m

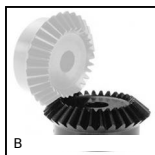

B

Ingranaggio conico - Acciaio 60C40, 1:1

Prodotti correlati



BEAS

Star shaped anti-static handle, Star, anti-static



PAS

Maniglia a ponte, Reinforced PA thermoplastic



BEAS

Manopola, stella, antistatico