

Antistatic knurled nut

EMAS Prevents occurrence of electrostatic spark

Eliminates electrical charges

- Materials :

Reinforced PA thermoplastic, graphite black
Tapped bush in steel trivalent blue passivated

Advantages



- These products can be used for electrostatic discharge applications or areas where electrostatic discharge protection (EPA) in accordance with DIN EN61340-5-1
- The knurled nuts can be tightened or loosened without tools



NEW!



Antistatic

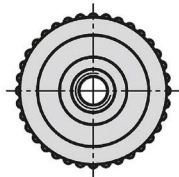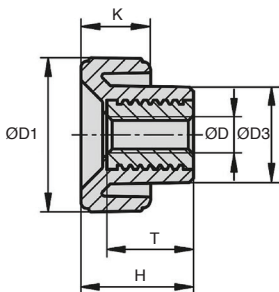

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	ØD1	ØD3	H	K	T	Price each
							1 to 9
EMAS18-M4	M4	18	11	13	8	10	6,12 €
EMAS20-M5	M5	20	13,6	15	9	10	6,61 €
EMAS25-M6	M6	25	14	17	10	10	7,24 €
EMAS32-M8	M8	32	18	22	13	14	8,30 €
EMAS40-M10	M10	40	19	25	14	14	9,03 €

Dimensions in mm

Altri prodotti...



BABpss

Perno autobloccante,
Inox



INS_SS

Inserto auto-filettante,
Inox 316




DER71

Motore inox AC
asincrono da 0,25 a
0,37kW, 0.25 a
0,37kW



GCL

Guida lineare a sfere -
Sfere inox, Carello -
da 516 N a 8396 N

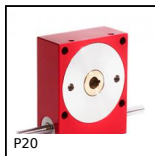

P20

Riduttore a ruota e
vite senza fine, fino a
5 Nm



BOX-NINA

Dado autofrenante -
DIN985, Valigetta di
dadi acciaio



PLA

Magnete, Magnete
piatto con foro
maschiato



INS_SS

Boccola autofilettante
Inox, Inox



PRF_PF

Elementi di
ancoraggio, Staffa di
fissaggio



IN1

Ingranaggio interno,
Acciaio 20NCD2



GPBSS

Impugnatura sferica
femmina filettata,
Alluminio



PM4

Coppia ruota e vite
senza fine, Acciaio
non temprato

Prodotti correlati



BEAS

Star shaped anti-
static handle, Star,
anti-static



PAS

Maniglia a ponte,
Reinforced PA
thermoplastic



BEAS

Manopola, stella,
antistatico