

Narrow wing nuts




EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:
 - Stainless steel 1.4404 (316L)
 - Polished finish <math>< Ra 0.8 \mu m</math>

Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

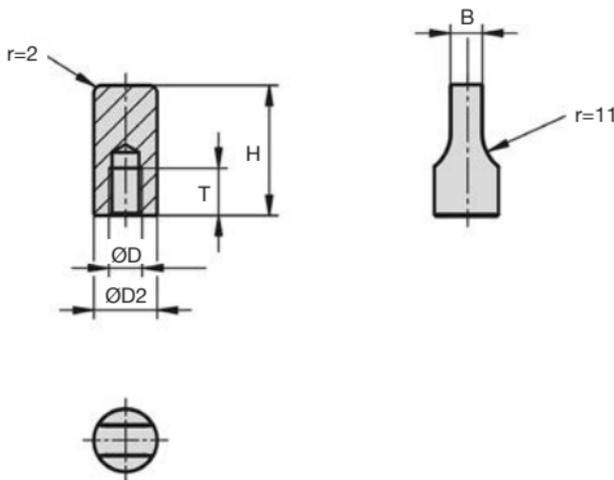

DISCOUNTS

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request

Part N°	ØD	ØD2	H	B	T	Price each
						1 to 4
EPE-4/HDSS	M4	9	20	4,5	6	11,69 €
EPE-5/HDSS	M5	10	22	4,5	6	12,12 €
EPE-6/HDSS	M6	12	22	5,5	7	13,20 €
EPE-8/HDSS	M8	16	25	8,0	9	13,62 €
EPE-10/HDSS	M10	20	30	10,0	11	14,52 €

All dimensions in mm

Altri prodotti...



TCXR

Tenditore per catena automatico, Con pignone acciaio



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



PRF_PIV

Cerniere e giunti, Fulcro per porta



DOMI30

Kit di raccordo, Kit di raccordo XY



PSG08

Ingranaggio dritto di precisione, Acciaio 35NCD6 pretrattato



S_2RS

Cuscinetto radiale a sfere, Inox



GCT

Copiglia per tubo, Clip per tubo



PTMC

Telescopio furniture foot, square plate



RBGtc

Ruota girevole a foro centrale, Acciaio - gomma grigia - a doppio bl...



DZYSS

Piedino antivibrante cilindrico inox, inox



PSG125

Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato



PRES

Accessori per pressa PRES-3HR e PRES-4HR, Regolazione micrometrica (...)

Prodotti correlati