

# Narrow wing nuts




EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:
  - Stainless steel 1.4404 (316L)
  - Polished finish <math>< Ra 0.8 \mu m</math>

## Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

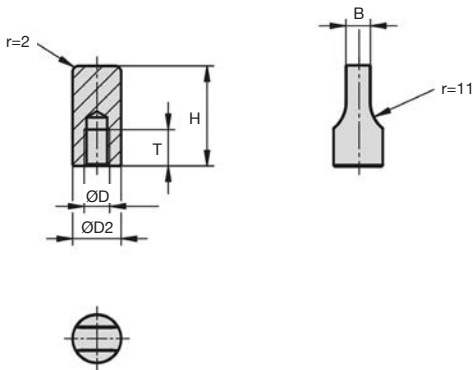


## DISCOUNTS

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request

Part N°	ØD	ØD2	H	B	T	Price each
						1 to 4
EPE-4/HDSS	M4	9	20	4,5	6	11,69 €
EPE-5/HDSS	M5	10	22	4,5	6	12,12 €
EPE-6/HDSS	M6	12	22	5,5	7	13,20 €
EPE-8/HDSS	M8	16	25	8,0	9	13,62 €
EPE-10/HDSS	M10	20	30	10,0	11	14,52 €

All dimensions in mm

## Altri prodotti...

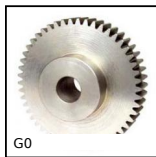

G0

Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



BABam

Perno di sollevamento  
autobloccante,  
Autobloccante



PSPD18

Manopola a pressione,  
PVC nero



PR65C

Half-articulated foot Ø  
65, Ø 65



T5-10ECO

Puleggia dentata di  
posizionamento tipo  
T, Serie economica -  
T5 allu...



RFVbr

Riduttore inox a ruota  
e vite senza fine,  
Braccio di reazione




MSP23

Inserto con piastrina a  
incollare  
Masterplate®,  
Cilindrico Ø23 con...



CHMR75

Riduttore a ruota e  
vite senza fine, fino a  
298 Nm

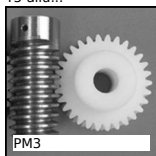

PM3

Coppia ruota e vite  
senza fine, Plastica



PRF\_PIV

Cerniere e giunti,  
Fulcro per porta



BOXKU

Box kit di chiavette a  
disco, Box kit di



GDR880

Guida dritta, Serie  
880 e 881

**Prodotti correlati**