

Narrow wing nuts





EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:
Stainless steel 1.4404 (316L)
Polished finish <math>< Ra 0.8 \mu m</math>

Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

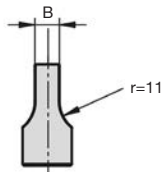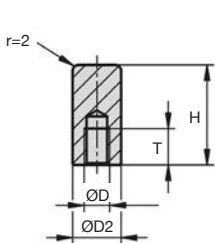


DISCOUNTS

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request

Part N°	ØD	ØD2	H	B	T	Price each
						1 to 4
EPE-4/HDSS	M4	9	20	4,5	6	11,69 €
EPE-5/HDSS	M5	10	22	4,5	6	12,12 €
EPE-6/HDSS	M6	12	22	5,5	7	13,20 €
EPE-8/HDSS	M8	16	25	8,0	9	13,62 €
EPE-10/HDSS	M10	20	30	10,0	11	14,52 €

All dimensions in mm

Altri prodotti...

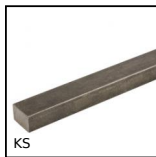

KS

Chiavetta in barre,
Acciaio - in barre



SCH

Attrezzo di bloccaggio
a tirante, A tirante
orizzontale - acciaio



KSTM

Supporto ritto con
cuscinetto Igubal®,
Polimero



PTCR

Adjustable furniture
foot, square tube



DBC

Panamech, Multi-
Beam, Alluminio - con
ganascia di serraggio



HCSS

Grano con punta a
coppa, punta a coppa



GLT3E-58

Guide telescopiche
acciaio, Estensione
extra



SVG

Chiusura a leva
regolabile, Corsa da
106,7mm a 121,4mm



PSP

Accessori per
pannello, Profilo
supporto per pannelli



BLH50

Rinvio angolare a L,
da 7.70 a 20 Nm



PDD

Pressore a molla
sensore di
rilevamento, Con



PTRSS

Pignone tendicatena,
Per ambienti
aggressivi

Prodotti correlati