

Quick fitting cable terminals

Sta

ERCss
ERLss

Fork and eye versions

- Cable terminals for wires, manual crimping

- Material: Stainless steel 316

Advantages

- Rapid manual assembly




ERL Eye




ERC Fork

stainless steel



Manually crimped

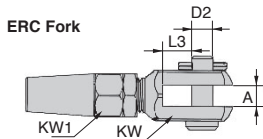

ERC Fork

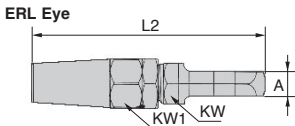

ERL Eye

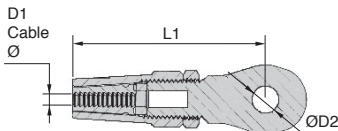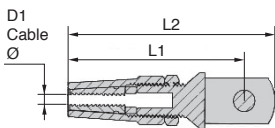

DISCOUNTS

Qty.	1+	6+	20+	50+
Disc.	Price -10%	-20%	On request	

Part number	ØD1	ØD2	A	L1	L2	L3	KW	KW1	Weight (g)	Price each 1 to 5
Fork										
ERC3-6/SS	3	6	6,25	49,0	57,0	8,0	12	14	40	24,84 €
ERC4-8/SS	4	8	7,90	60,5	71,4	8,3	14	19	80	29,21 €
ERC5-10/SS	5	10	9,70	69,0	79,0	10,0	16	22	120	34,52 €
ERC6-12/SS	6	12	11,00	81,0	93,0	12,0	19	27	210	43,41 €
ERC8-14/SS	8	14	13,00	106,0	120,0	15,0	24	30	376	59,71 €
Eye										
ERL3-6/SS	3	6	6	48	57	-	10	12	34	26,04 €
ERL4-8/SS	4	8	7	56	69	-	14	14	62	29,72 €
ERL5-10/SS	5	10	8	66	82	-	14	16	88	35,06 €
ERL6-13/SS	6	13	9	83	100	-	17	19	154	42,80 €
ERL8-14/SS	8	14	10	102	123	-	19	24	278	56,40 €

Altri prodotti...




UGCC
Unità di guida per cilindrico, Colonna di guida



PRF19_E
Squadra di giunzione, PRF19 a PRF32



CNA-CNG
Staffa di montaggio per molla a gas, Staffa di montaggio a squadra p...

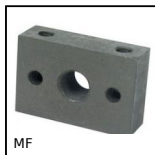

MF
Deceleratore, Flangia rettangolare



PRF-SCREEN-5
Screen support, Support with 5 axes of rotation



MEB
Ingranaggio conico in plastica stampata, 1:1



LRM2
Dado trapezoidale, Bronzo - 2 filetti



PSG1
Ingranaggio dritto di precisione, Acciaio 35NCD6 pretrattato



SBF
Sealed flange bearing unit for Food Industry,



LR
Cuscinetti a sfere - Accessorio, Ghiera di



WJRM
Pattino ibrido Drylin® W, Cuscinetto ibrido




RAM30
Riduttore manuale, Rinvio angolare


Prodotti correlati



ERC
Terminale rapido per cavi, A forcella

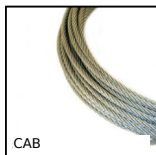

CAB
Cavo di fissaggio, Inox

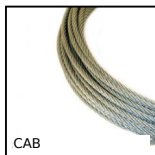

CAB
Cavo di fissaggio, Acciaio galvanizzato



CABPVC
Cavo acciaio galvanizzato con PVC trasparente, Acciaio galvanizzato ...