

Simple support base (bipod)



ESSBNV


Plastic

- **Bipod support base**
- Component for conveyor structure
- For round tube
- Materials
 - Body: reinforced polyamide
 - Screws: stainless steel 304



Accessories

- Add compatible **PR** feet to order (tome 5 p.169)

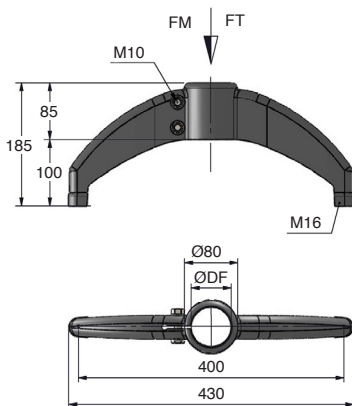

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDF	Max. load resistance FM (N)	Max. working load FT (N)	Weight (kg)	Price each 1 to 4
ESSB-42/NV	42,4	15800	9600	0,612	43,57 €
ESSB-48/NV	48,3	15800	9600	0,612	43,57 €
ESSB-50/NV	50,8	15800	9600	0,612	43,57 €
ESSB-60/NV	60,3	15800	9600	0,752	43,57 €

Dimensions in mm


- **Combined bipod support part**
- Component for conveyor structure
- For round tube
- Materials
 - Body: reinforced polyamide
 - Screws: stainless steel 304

Accessories

- Add compatible PR feet to order (tome 5 p.169)



Typical application

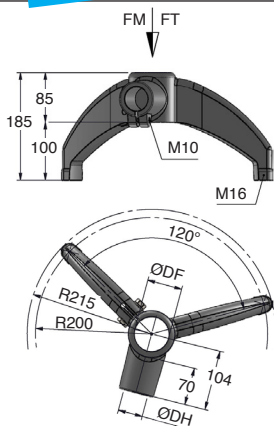

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	ØDH	Max load resistance.FM (N)	Max. working load FT (N)	Weight (kg)	Price each 1 to 4
ESCB-42-42/NV	42,4	42,4	15800	9600	0,925	51,82 €
ESCB-48-42/NV	48,3	42,4	15800	9600	0,925	51,82 €
ESCB-48-48/NV	48,3	48,3	15800	9600	0,925	51,82 €
ESCB-50-42/NV	50,8	42,4	15800	9600	0,925	51,82 €
ESCB-50-48/NV	50,8	48,3	15800	9600	0,925	51,82 €
ESCB-60-42/NV	60,3	42,4	15800	9600	0,925	51,82 €
ESCB-60-48/NV	60,3	48,3	15800	9600	0,925	51,82 €

Dimensions in mm


- **High stability**
- Component for conveyor structure
- For round tube
- Materials:

Body: reinforced polyamide



Screws: stainless steel 304

Accessories

- Add compatible **PR** feet to order (tome 5 p.169)

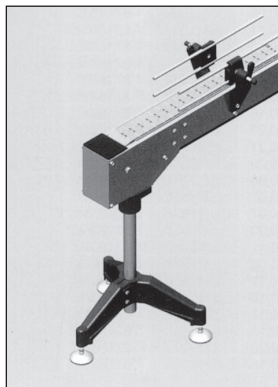

Typical application

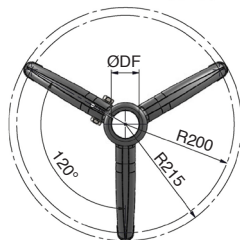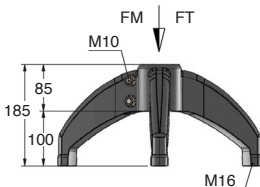

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	Max. load resistance FM (N)	Max. working load. FT (N)	Weight (kg)	Price each 1 to 4
ESST-42/NV	42,4	15800	9600	0,975	49,46 €
ESST-48/NV	48,3	15800	9600	0,975	49,46 €
ESST-50/NV	50,8	15800	9600	0,975	49,46 €
ESST-60/NV	60,3	15800	9600	0,975	49,46 €

Dimensions in mm

Altri prodotti...



DOMI120

Kit di raccordo, Kit di raccordo XY



RFK58C

Riduttore ipoide inox, fino a 500 Nm



ACLEPP

Angolare, 2 fori



YG0

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



PSG125

Ingranaggio dritto di precisione, Acciaio 35NCD6 pretrattato



KK

Chiavetta rettangolare, Acciaio



BABreceptacle

Perno autobloccante, Bussola di innesto



SBF

Sealed flange bearing unit for Food Industry, cover



MEB

Ingranaggio conico in plastica stampata, 1:1



WW10

Guida Drylin® W, Carrello



QTR

Cuscinetto a rulli conici, Acciaio



DOMI120

Accessori di collegamento, Piastra

Prodotti correlati



ES

Simple support base (bipod), Plastic



ES

Bipod support base, Plastic



PR40

Piede fissabile con snodo - poliammide, Ø 40



PR40

Piede fissabile con snodo - poliammide, Ø 50