

# Simple support base (bipod)



## ESSBNV


## Plastic

- **Bipod support base**
- Component for conveyor structure
- For round tube
- Materials
  - Body: reinforced polyamide
  - Screws: stainless steel 304



### Accessories

- Add compatible **PR** feet to order (tome 5 p.169)

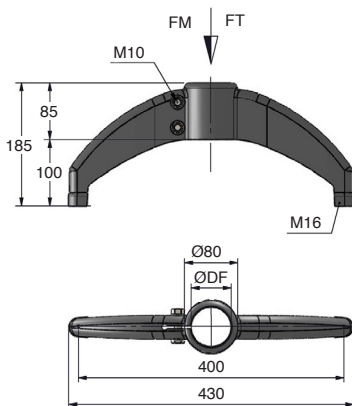

### DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDF	Max. load resistance FM (N)	Max. working load FT (N)	Weight (kg)	Price each 1 to 4
ESSB-42/NV	42,4	15800	9600	0,612	43,57 €
ESSB-48/NV	48,3	15800	9600	0,612	43,57 €
ESSB-50/NV	50,8	15800	9600	0,612	43,57 €
ESSB-60/NV	60,3	15800	9600	0,752	43,57 €

Dimensions in mm


- **Combined bipod support part**
- Component for conveyor structure
- For round tube
- Materials
  - Body: reinforced polyamide
  - Screws: stainless steel 304

### Accessories

- Add compatible PR feet to order (tome 5 p.169)



Typical application

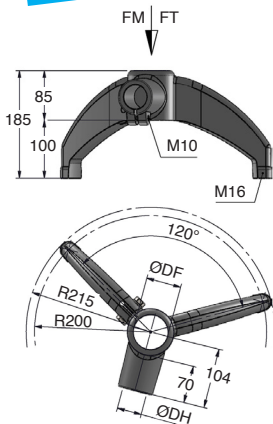

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	ØDH	Max load resistance.FM (N)	Max. working load FT (N)	Weight (kg)	Price each 1 to 4
ESCB-42-42/NV	42,4	42,4	15800	9600	0,925	51,82 €
ESCB-48-42/NV	48,3	42,4	15800	9600	0,925	51,82 €
ESCB-48-48/NV	48,3	48,3	15800	9600	0,925	51,82 €
ESCB-50-42/NV	50,8	42,4	15800	9600	0,925	51,82 €
ESCB-50-48/NV	50,8	48,3	15800	9600	0,925	51,82 €
ESCB-60-42/NV	60,3	42,4	15800	9600	0,925	51,82 €
ESCB-60-48/NV	60,3	48,3	15800	9600	0,925	51,82 €

Dimensions in mm


- **High stability**
- Component for conveyor structure
- For round tube
- Materials:

Body: reinforced polyamide



Screws: stainless steel 304

### Accessories

- Add compatible **PR** feet to order (tome 5 p.169)

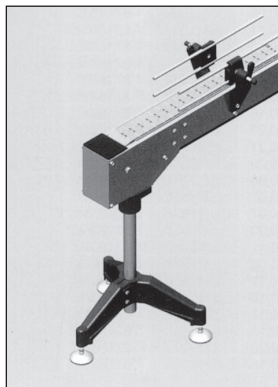

Typical application

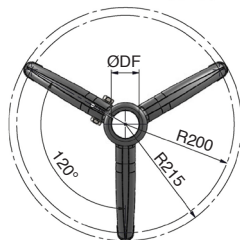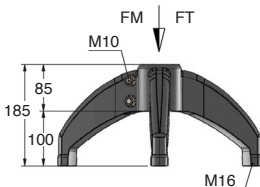

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	Max. load resistance FM (N)	Max. working load. FT (N)	Weight (kg)	Price each 1 to 4
ESST-42/NV	42,4	15800	9600	0,975	49,46 €
ESST-48/NV	48,3	15800	9600	0,975	49,46 €
ESST-50/NV	50,8	15800	9600	0,975	49,46 €
ESST-60/NV	60,3	15800	9600	0,975	49,46 €


Dimensions in mm

## Altri prodotti...



R203

Molla per stampi  
ISO10243, Leggero

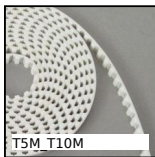

T5M T10M

Cinghia aperta al  
metro tipo T, T10  
Poliuretano armatura  
in acciaio



BAGSS

Anello di bloccaggio  
inox, Inox



SSB

Ingranaggio conico  
inox, 1:1




PRF\_GAL

Rotella per profilo  
alluminio, Kit di  
fissaggio per rotella  
concentr...



MSP3815

Inserito con piastrina a  
incollare  
Masterplate®,  
rettangolare con dado

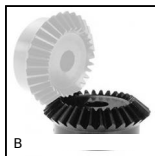

B

Ingranaggio conico -  
Acciaio 60C40, 1:1



HTD8M\_50

Puleggia dentata di  
trasmissione tipo  
HTD, HTD8 Acciaio



OP6

Indicatore di posizione  
digitale (N. di giri), 5  
cifre



PRF\_BV

Bloccetto di  
fissaggio, Aggiunta e  
fissaggio di pannelli



M2

Vite senza fine,  
Acciaio temprato



MSP38

Inserito con piastrina a  
incollare  
Masterplate®,  
Cilindrico Ø38 con...

## Prodotti correlati



ES

Support base (tripod),  
Plastic



ES

Simple support base  
(bipod), Plastic



PR40

Piede fissabile con  
snodo - poliammide, Ø  
40



PR40

Piede fissabile con  
snodo - poliammide, Ø  
50