

Simple support base (bipod)



ESSBNV


Plastic

- **Bipod support base**
- Component for conveyor structure
- For round tube
- Materials

Body: reinforced polyamide
Screws: stainless steel 304

Accessories

- Add compatible **PR** feet to order (tome 5 p.169)

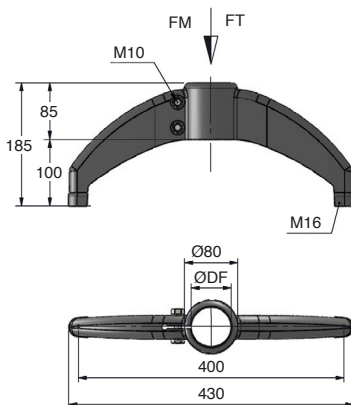

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	Max. load resistance FM (N)	Max. working load FT (N)	Weight (kg)	Price each 1 to 4
ESSB-42/NV	42,4	15800	9600	0,612	43,57 €
ESSB-48/NV	48,3	15800	9600	0,612	43,57 €
ESSB-50/NV	50,8	15800	9600	0,612	43,57 €
ESSB-60/NV	60,3	15800	9600	0,752	43,57 €

Dimensions in mm

- **Combined bipod support part**
- Component for conveyor structure
- For round tube
- Materials

Body: reinforced polyamide


Screws: stainless steel 304

Accessories

- Add compatible PR feet to order
(tome 5 p.169)



Typical application

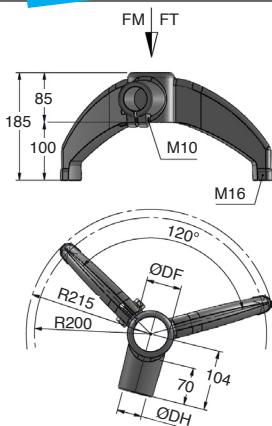

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	ØDH	Max load resistance.FM (N)	Max. working load FT (N)	Weight (kg)	Price each 1 to 4
ESCB-42-42/NV	42,4	42,4	15800	9600	0,925	51,82 €
ESCB-48-42/NV	48,3	42,4	15800	9600	0,925	51,82 €
ESCB-48-48/NV	48,3	48,3	15800	9600	0,925	51,82 €
ESCB-50-42/NV	50,8	42,4	15800	9600	0,925	51,82 €
ESCB-50-48/NV	50,8	48,3	15800	9600	0,925	51,82 €
ESCB-60-42/NV	60,3	42,4	15800	9600	0,925	51,82 €
ESCB-60-48/NV	60,3	48,3	15800	9600	0,925	51,82 €

Dimensions in mm


- **High stability**
- Component for conveyor structure
- For round tube
- Materials:

Body: reinforced polyamide


Screws: stainless steel 304

Accessories

- Add compatible **PR** feet to order
(tome 5 p.169)

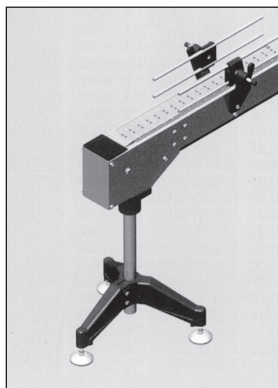

Typical application

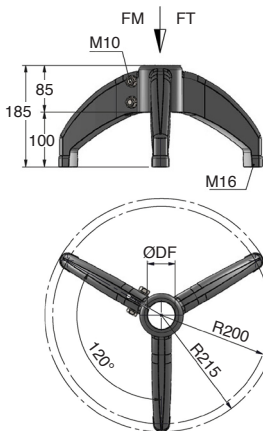

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	Max. load resistance FM (N)	Max. working load. FT (N)	Weight (kg)	Price each 1 to 4
ESST-42/NV	42,4	15800	9600	0,975	49,46 €
ESST-48/NV	48,3	15800	9600	0,975	49,46 €
ESST-50/NV	50,8	15800	9600	0,975	49,46 €
ESST-60/NV	60,3	15800	9600	0,975	49,46 €

Dimensions in mm

Altri prodotti...



RFVcap

Coperchio di protezione inox,
Coperchio di protezione chiuso



UCP_PBT

Cuscinetto ritto polimero inox,
polimero e inox



MCLred

Manicotto di riduzione, Cilindrico -



BDM

Perno ad innesto per
boccola magnetica,
Bloccaggio magnetico
rapido ...




PSG05S

Ingranaggio dritto di
precisione, Inox 303



T5courroie

Cinghia di
posizionamento T, T5
Poliuretano armatura
in acciaio

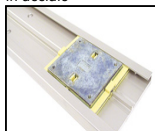

NK80

Guida mini Drylin® N,
Larghezza 80mm



PR880

Ruota di rinvio, Serie
880



EBH

Dado cieco Hygienic
Design®, Con collare



G0

Ingranaggio dritto
acciaio, Acciaio



TBE16

Economic mini-table
with trapezoidal



PTGR

Puleggia folle, Per
cinghia tonda

Prodotti correlati



ES

Support base (tripod),
Plastic



ES

Simple support base
(bipod), Plastic



PR40

Piede fissabile con
snodo - poliammide, Ø
40



PR40

Piede fissabile con
snodo - poliammide, Ø
50