

Simple support base (bipod)



ESSB


Plastic

- **Bipod support base**
- Component for conveyor structure
- For round tube
- **Materials**
 - Body: Reinforced polyamide
 - Inserts: Nickel brass
 - Screws: stainless steel



Accessories

- Compatible **PR** Feet

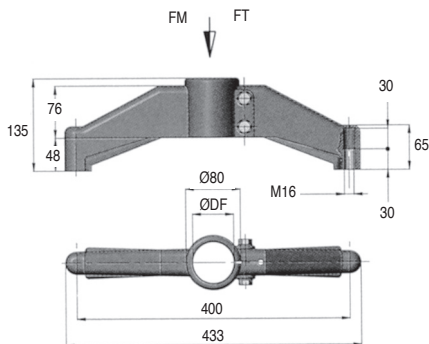

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List -5%	On request	

Part number	ØDF	Max. load resistance FM (N)	Max. working load FT (N)	Weight (kg)	Stock*	Price each 1 to 4
ESSB-42	42,4	12000	8000	1,03	✓	36,65 €
ESSB-48	48,3	12000	8500	1,01	✓	36,65 €
ESSB-50	50,9	12000	9000	0,99	✓	36,65 €
ESSB-60	60,3	12000	10000	0,97	✓	36,65 €

*Depending on availability - Dimensions in mm

Altri prodotti...



HTD8M_20
Puleggia dentata di trasmissione tipo HTD, HTD8 Acciaio



HDSS
Giunto cardanico - inox, Sollecitazioni intense



FBL4004_K7
Spazzola al metro fibre PA6 da Ø0,3 a Ø0,5, Poliammide nero 6 - me...




RFK58C
Riduttore ipoide inox, fino a 500 Nm



BC3
Panamech, Multi-Beam inox, Inox - con ganascia di serraggio



VTLF
Volantino a 3 lobi, Poliammide - Ottone

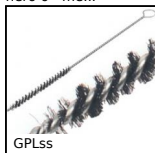

GPLss
Scovolo, inox



MEB
Ingranaggio conico in plastica stampata, 1:1



PSG05S
Ingranaggio dritto di precisione, Inox 316



SERB
Interblocco di sicurezza, Chiave universale per



ACLEPP
Angolare, 4 fori



gt64r
Chiusura a farfalla a molla, Tolleranze di montaggio ampie

Prodotti correlati



PR40
Piede fissabile con snodo - poliammide, Ø 40



ESST
Base di sostegno, Tre piede