



- **High stability**
- Component for conveyor structure
- For round tube
- Materials:
 - Body: Reinforced polyamide
 - Inserts: Nickel brass
 - Screws: stainless steel

Accessories

- Compatible **PR** Feet



Typical application

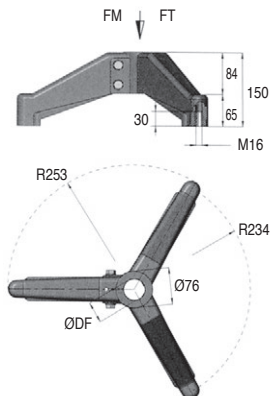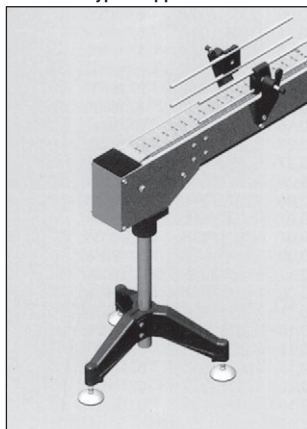

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List -5%	On request	On request

Part number	ØDF	Max. load resistance FM (N)	Max. working load FT (N)	Weight (kg)	Stock*	Price each 1 to 4
ESST-42	42,4	16000	8000	1,90	✓	40,88 €
ESST-48	48,3	16000	8500	1,90	-	39,74 €
ESST-50	50,9	16000	9000	1,90	✓	41,59 €
ESST-60	60,3	16000	10000	1,90	✓	37,05 €

*Depending on availability - Dimensions in mm

Altri prodotti...



MDB_MTB
Ingranaggio conico in
plastica stampata ,
3:1



TBE12
Economic mini-table
with trapezoidal
leadscrew, 2kg



CFF
Testa a snodo
femmina DIN
ISO12240-4, Acciaio /
bronzo



AZY_SS
Antivibrante elastico
cilindrico inox, Inox



INS_BR
Boccola autofilettante
Ottone, Ottone



ACLAPA
Sistema di chiusura,
Battuta a calamita



RT61ss
Calettatore di
bloccaggio, Coppia
media/bassa



UCF_PBT
Cuscinetto a flangia
quadrata polimero
inox, Polimero e inox



GEC
Chiusura a leva in
gomma con aggancio,
Bloccabile



CHM63-MOT
Motoriduttore AC
asincrono 0,37 a
1,5kW, 0.37 a 1.5kW



TCC_SS
Tenditore, Inox



BUT
Accessori per
pannello, Arresto per
pannello

Prodotti correlati



PR40
Piede fissabile con
snodo - poliammide, Ø
40



ESSB
Base di sostegno,
Bipiede singolo