


- Cable terminal to be screwed
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

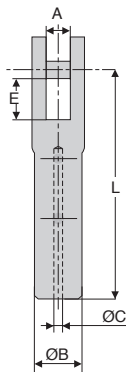

DISCOUNTS

Qty	1+	4+	10+	15+
Disc. List	-10%	-20%	On request	


Part number	For cable					Weight (g)	Price each 1 to 3
	ØC	A	ØB	C	L		
EVC2-37/SS	2	4,5	8	7	37	16,5	
EVC3-50/SS	3	5,5	10	8	50	30,0	
EVC4-52/SS	4	6,5	12	8	52	46,0	

Dimensions in mm

- Cable terminal to be screwed
- Thread ISO pitch right hand
- Delivered with a nut
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

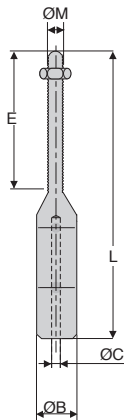

DISCOUNTS

Qty	1+	4+	10+	15+
Disc.	List	-10%	-20%	On request


Part number	For cable			E	L	Weight (g)	Price each 1 to 3
	ØC	ØM	ØB				
EVF2-50-M4/SS	2	M4	8	20	50	11,0	
EVF3-56-M4/SS	3	M4	10	20	56	19,0	
EVF4-80-M5/SS	4	M5	12	40	80	51,5	

Dimensions in mm

- Cable terminal to be screwed
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

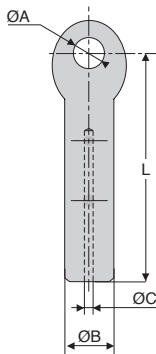

DISCOUNTS

Qty	1+	4+	10+	15+
Disc. List	-10%	-20%	On request	


Part number	For cable			L	Weight (g)	Price each 1 to 3
	ØC	ØA	ØB			
EVY2-37/SS	2	4,5	8	37	13	
EVY3-50/SS	3	5,5	10	50	27	
EVY4-52/SS	4	6,5	12	52	41	

Dimensions in mm

- Cable terminal to be screwed
- Thread ISO pitch right hand
- Delivered with a nut
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

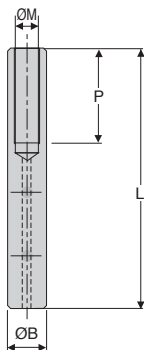


DISCOUNTS

Qty	1+	4+	10+	15+
Disc.	List	-10%	-20%	On request

Part number	For cable			P	L	Weight (g)	Price each 1 to 3
	ØC	ØM	ØB				
EVT2-55-M5/SS	2	M5	8	20	55	16,0	
EVT3-65-M5/SS	3	M5	10	25	65	33,0	
EVT4-70-M6/SS	4	M6	12	25	70	51,5	

Dimensions in mm

Altri prodotti...

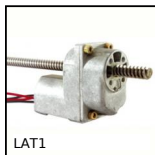


LAT1
Attuatore lineare a motore, 1 ampere



ZBconique
Ingranaggio conico in plastica, 1:1



SH1
Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)

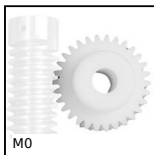

M0
Ruota per vite senza fine, Plastica lavorata (delrin)



EPRC
Dado cilindrico a passo lungo, Dado cilindrico-fino a 40mm di corsa ...



BTC
Tappo per tubo quadrato, Standard



PRFSRAD
Sistema di chiusura per profili alluminio, Serratura doppia rapida a...




D19 D29
Molla di compressione al metro inox, al metro




RTN
Giunto Bowex®, a dentatura bombata, Nylon



DOMI120
Slitta di regolazione Domino 120, Slitta DOMILINE 120

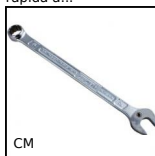

CM
Attrezzi Hygienic Usit® and Hygienic Design®, Combination spanner

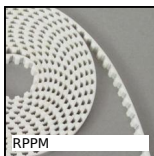

RPPM
Cinghia aperta al metro tipo RPP, RPP14 Poliuretano armatura in acci...

Prodotti correlati