

- **Indicator with an external sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6B battery (Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:

Sensor: Black anodised aluminium


Display housing: Plastic

NEW!



Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

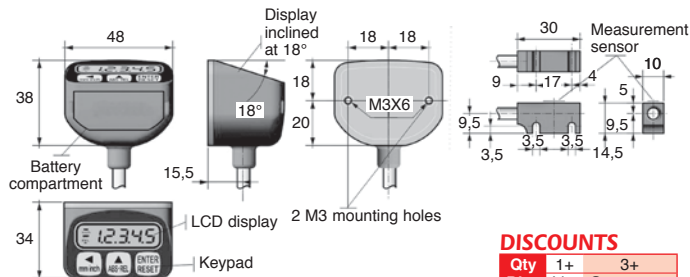

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Length of sensor (mm)	Price each 1 to 2
F7-E-A-500	A	500	378,94 €
F7-E-A-1000	A	1000	378,94 €
F7-E-A-3000	A	3000	401,27 €
F7-E-A-5000	A	5000	423,60 €
F7-E-B-500	B	500	378,94 €
F7-E-B-1000	B	1000	378,94 €
F7-E-B-3000	B	3000	401,27 €
F7-E-B-5000	B	5000	423,60 €

Dimensions in mm

Altri prodotti...



SLBS
Pistoncino a molla,
Tutto inox



KBS_UU
Manicotto chiuso a
sfere inox di
precisione, Di
precisione - inox / ...



RAS
Snodo angolare a 90°
DIN71802, Inox



GAL 42
Rullo per
trasportatore, Senza
cuscinetti a sfere



PAS
Maniglia a ponte,
Reinforced PA
thermoplastic



BPHF
Sfera portante a
incastro con flangia,
Forte




NPTR10
Connettore rinvio
d'angolo, Regolabile



AC
Piastrina di riscontro,
15mm



H02SS
Giunto cardanico
semplice ad aghi -
inox, Sollecitazioni

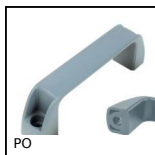

PO
Maniglia a ponte -
Multi-settore, Foro
liscio



PRFSRAD
Sistema di chiusura
per profili alluminio,
Serratura doppia



GG1
Ingranaggio dritto
rettificato, Acciaio
trattato

Prodotti correlati



F7-P-AM
Visualizzatore
multifunzione, Banda
magnetica



F7-P-AM
Visualizzatore
multifunzione, Anello
magnetico