

- **Indicator with an external sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6B battery (Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:

Sensor: Black anodised aluminium


Display housing: Plastic

NEW!



Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

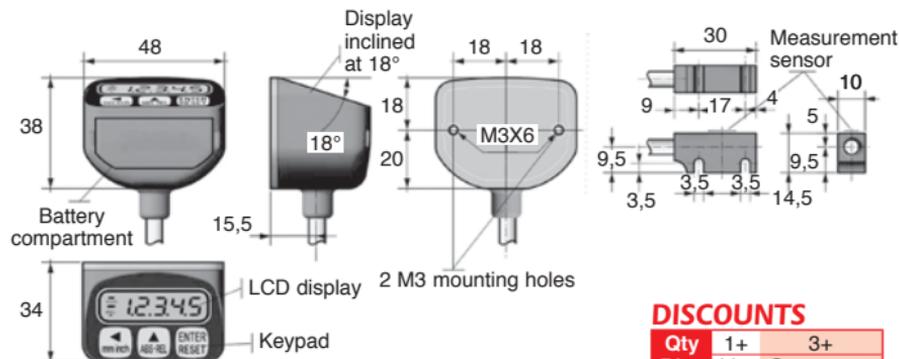

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Length of sensor (mm)	Price each 1 to 2
F7-E-A-500	A	500	378,94 €
F7-E-A-1000	A	1000	378,94 €
F7-E-A-3000	A	3000	401,27 €
F7-E-A-5000	A	5000	423,60 €
F7-E-B-500	B	500	378,94 €
F7-E-B-1000	B	1000	378,94 €
F7-E-B-3000	B	3000	401,27 €
F7-E-B-5000	B	5000	423,60 €

Dimensions in mm

Altri prodotti...



PR820

Ruota di rinvio, Serie 820 e 815



FF10

Riduttore ad alberi paralleli, da 0.78 a 3.70 Nm



BOX-TOR-D

Valigetta di guarnizioni toriche in nitrile, 18.00 x 2.00mm a 50.00 ...



MHX

Manicotto esagonale maschiato, Esagonale - acciaio



PSG3

Ingranaggio dritto di precisione, Acciaio 35NCD6 pretrattato



ALIDR30

Alimentazione, 1,5 A and 2 A



RFKfp

Riduttore inox - accessori, Piede di supporto



PW_PWG3

Vite senza fine di precisione, Acciaio



P70

Riduttore a ruota e vite senza fine, fino a 164 Nm



ESCON

Accessori per variatore di velocità 5A, Cavo USB per connessione PC



LACM_SS

Leva a camma inox, Femmina



LRH

Vite trapezoidale a doppia inclinazione, a doppia inclinazione - 1 f...

Prodotti correlati



F7-P-AM

Visualizzatore multifunzione, Banda magnetica



F7-P-AM

Visualizzatore multifunzione, Anello magnetico