

- **Indicator with an external sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6B battery (Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:

Sensor: Black anodised aluminium


Display housing: Plastic

NEW!



Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

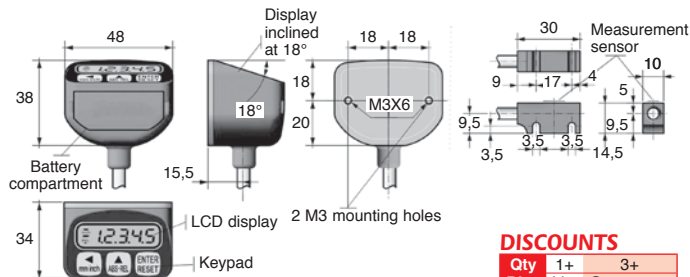

DISCOUNTS

| Qty | 1+ | 3+ |
|------|------|------------|
| Disc | List | On request |

| Part number | View | Length of sensor (mm) | Price each 1 to 2 |
|-------------|------|-----------------------|-------------------|
| F7-E-A-500 | A | 500 | 378,94 € |
| F7-E-A-1000 | A | 1000 | 378,94 € |
| F7-E-A-3000 | A | 3000 | 401,27 € |
| F7-E-A-5000 | A | 5000 | 423,60 € |
| F7-E-B-500 | B | 500 | 378,94 € |
| F7-E-B-1000 | B | 1000 | 378,94 € |
| F7-E-B-3000 | B | 3000 | 401,27 € |
| F7-E-B-5000 | B | 5000 | 423,60 € |

Dimensions in mm

Altri prodotti...



CHA225

Cerniera ad avvitare,
225 gradi



R203

Molla per stampi
ISO10243, Leggero



RBGpl

Ruota fissa con
piastra, Acciaio -
gomma grigia



SNG

Cuscinetto ritto
polimero inox, Ghisa -
In 2 metà



PPD

Pistoncino a molla,
Per lamiera



NKX

Cuscinetto combinato
senza anello interno,
Needle and roller
bearings



AT10-50ECO

Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT10 a...



ZY

Piedino antivibrante
cilindrico, Inox



BCH_SS

Pomello a fungo inox,
M3 a M8



EZYSS

Piedino antivibrante
cilindrico inox, inox



V3RA_PTR

Volantino a tre razze,
Poliammide



ACM_AZ

Aggancio per tirante
chiusura in gomma,
Aggancio

Prodotti correlati



F7-P-AM

Visualizzatore
multifunzione, Banda
magnetica



F7-P-AM

Visualizzatore
multifunzione, Anello
magnetico