

Multifunction display

New

F7-I

With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
 - Sensor: Black anodised aluminium
 - Display housing: Plastic

NEW!




View A



View B

Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

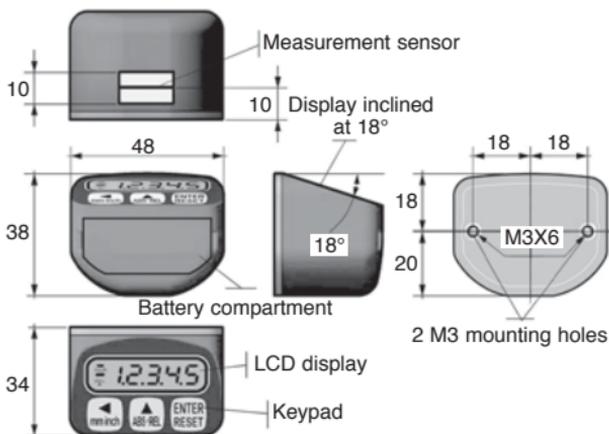

DISCOUNTS

Qty	1+	3+
Disc	List	On request


Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

Altri prodotti...



STU
Boccola a sfere
lineare e rotativa,
Acciaio

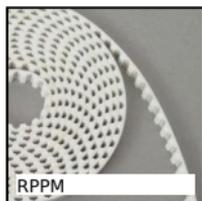

RPPM
Cinghia aperta al
metro tipo RPP, RPP5
Poliuretano armatura
in acciaio



CLB_M
Maniglia a ripresa,
Zamak



RBS
Rondella elastica ,
Acciaio



T39_T49
Molla di trazione al
metro inox, al metro



SMLS
Tavola lineare, Per
lunghezze ridotte



DBL821
Rotella per catena,
Serie 821



VCMB
Vite di giunzione
metallo/legno, Acciaio



BS3
Panamech, Multi-
Beam inox, Inox - con
vite a pressione



AC
Piastrina di riscontro,
15mm



SDC
Boccole di
posizionamento per
pistoncino a molla,
Acciaio



UTKswcr
Guida lineare
Utilitrack®, Carrello a
rotelle acciaio

Prodotti correlati



F7-SF-SM
Visualizzatore
multifunzione,
Supporto - montaggio
frontale



F7-SN
Visualizzatore
multifunzione,
Supporto snodato