

Multifunction display

New

F7-I

With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
 - Sensor: Black anodised aluminium
 - Display housing: Plastic

NEW!




View A



View B

Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

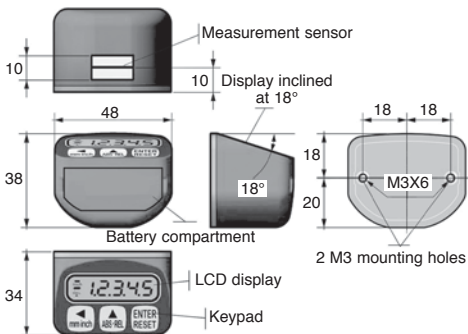

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

Altri prodotti...



DOG258

Motoriduttore DC 12V e 24V DC, da 12 a 15 Nm



ARTE

Silent block, Carico multidirezionale



PPF

Pistoncino a molla, con flangia



BLHB40

Rinvio angolare ad albero cavo, fino a 10.3 Nm



RDCss

Tenditore, Inox



BOX-TOR-ORFS

Valigetta di guarnizioni toriche in nitrile, 7.65 x 1.78mm a 37.82 x...



PMC150_M16

Supporto antivibrante a campana, Piastra a base quadrata



PRF4545_P

Profilato alluminio per camera bianca, 45 x 45 mm



GSI

Molla a gas inox, Inox



SSDB

Ingranaggio conico inox, 2:1



HRV

Sistema di guida su binario a V Simple Select®, Binario con



BCA

Ghiera scanalata cilindrica in acciaio, Acciaio

Prodotti correlati



F7-SF-SM

Visualizzatore multifunzione, Supporto - montaggio frontale



F7-SN

Visualizzatore multifunzione, Supporto snodato