

Sealing brush strips

FBL

Advantages and applications

Advantages



- No wastage, only the length required is removed from the roll.
- Reduced storage/transport space, each box contains 25 metres.



- Special scissors allow the strip to be cut to the required length.




- Flexible in terms of positioning and fitting.

Applications



- Splash guard for wheel arches on a lorry

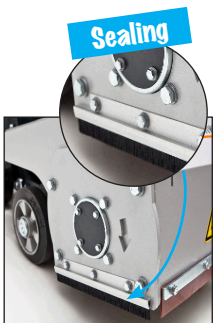

- Waterproofness of floor cleaning machines



- Guiding PET bottles

Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

FBL6000
FBL6001

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
 - **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- Maximum temperature: +150°C
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

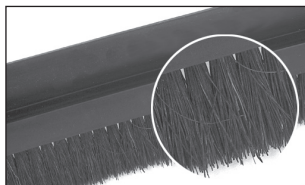

Horsehair fibres

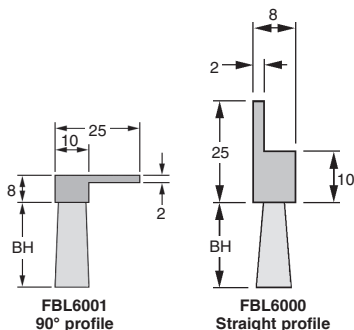

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
Black horsehair							
FBL6000-K19	0,2	15	5m	✓	-	63,64 €	-
FBL6000-K20	0,2	20	5m	✓	-	68,86 €	-
FBL6000-K21	FBL6001-K21	0,2	25	5m	-	✓	74,33 € 74,33 €
FBL6000-K23	FBL6001-K23	0,2	40	5m	✓	✓	92,79 € 92,79 €
FBL6000-K24	FBL6001-K24	0,2	50	5m	✓	✓	108,10 € 108,10 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip PA6 fibres Ø0.2 to Ø0.3 Stock

FBL6000 FBL6001

For ensuring an internal seal

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
- **Working temperature:** -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- **Working temperature:** -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

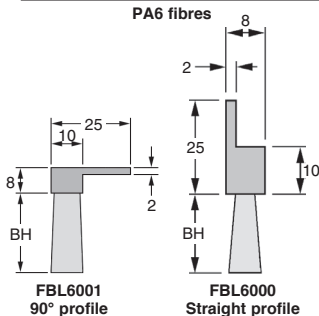

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres								
FBL6000-K1	FBL6001-K1	0,2	10	5m	✓	✓	48,53 €	48,53 €
FBL6000-K2	FBL6001-K2	0,2	15	5m	✓	✓	49,78 €	49,78 €
FBL6000-K3	FBL6001-K3	0,2	20	5m	✓	✓	51,26 €	51,26 €
FBL6000-K4	-	0,2	25	5m	✓	-	52,74 €	-
FBL6000-K5	FBL6001-K5	0,2	30	5m	✓	✓	54,21 €	54,21 €
FBL6000-K7	-	0,3	15	5m	✓	-	49,78 €	-
FBL6000-K8	-	0,3	20	5m	✓	-	51,26 €	-
FBL6000-K9	-	0,3	25	5m	✓	-	52,74 €	-
FBL6000-K10	-	0,3	30	5m	✓	-	54,21 €	-
FBL6000-K11	-	0,3	40	5m	✓	-	57,33 €	-
FBL6000-K12	-	0,3	50	5m	✓	-	60,29 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm



Brush strip PA6 fibres Ø0.3 to Ø0.5

For ensuring an internal seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length
FBL-TOOL



PA6 fibres

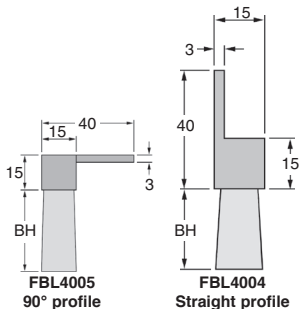

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
Straight profile	90° profile							
Black Polyamide 6 (PA6) fibres								
FBL4004-K8	-	0,3	20	5m	✓	-	140,75 €	-
FBL4004-K9	-	0,3	30	5m	✓	-	147,61 €	-
FBL4004-K13	-	0,5	30	5m	✓	-	147,61 €	-
FBL4004-K14	-	0,5	40	5m	✓	-	154,69 €	-
FBL4004-K15	-	0,5	50	5m	✓	-	161,80 €	-
FBL4004-K18	FBL4005-K15	0,5	80	5m	✓	✓	193,81 €	193,81 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip **PP fibres** Ø0.2



FBL6000 FBL6001

For ensuring an external seal

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts


Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals... Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals. Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL

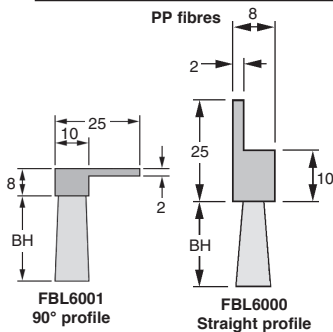

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Straight profile	90° profile	Bristle diameter (mm)	BH	Length	Stock*		Price each	
						Straight profile	90° profile	Straight profile	90° profile
Black horsehair									
FBL6000-K13	FBL6001-K13		0,2	10	5m	✓	✓	44,56 €	44,56 €
FBL6000-K14	FBL6001-K14		0,2	15	5m	✓	✓	44,98 €	44,98 €
FBL6000-K15	FBL6001-K15		0,2	20	5m	✓	✓	45,38 €	45,38 €
FBL6000-K17	FBL6001-K17		0,2	30	5m	✓	-	46,66 €	46,66 €
FBL6000-K18	FBL6001-K18		0,2	40	5m	✓	✓	47,69 €	47,69 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

For ensuring an external seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL

PP fibres

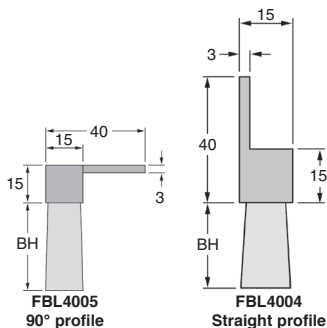**DISCOUNTS**

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
Black Polyamide 6 (PA6) fibres								
FBL4004-K34	-	0,3	30	5m	✓	-	130,13 €	-
FBL4004-K35	-	0,3	40	5m	✓	-	132,49 €	-
FBL4004-K36	FBL4005-K31	0,3	50	5m	✓	✓	134,99 €	134,99 €
FBL4004-K37	FBL4005-K32	0,3	60	5m	✓	-	137,47 €	137,47 €
FBL4004-K38	-	0,3	70	5m	✓	-	151,08 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Our other products



T type timing belt per metre, T5 Steel cored polyurethane



Elastic ringed latch, Hooks into a slot



Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



Internal epicyclic servo reducers, from 60 to 140 Nm




V shaped channel UtiliTrak®, V rail



Worm and wheel gear reducer, up to 298 Nm



End cap for round tube, Standard

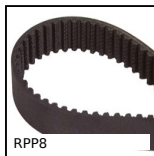

RPP heavy duty timing belt, RPP8



Mounting feet with integrated castors,



Worm - precision range, Steel



Speed controller 5A accessories, Kit of 4



Worm and wheel set, Hardened steel

Complementary products



Sealing brush strip, 3m length



Sealing brush strip, 1m length

Altri prodotti...



RHTtcss
Ruota alte temperature, fino a 200kg




SSG0
Ingranaggio dritto
Inox, Inox 304L



PAMF100EB
Piede snodato con base stampata fissabile Ø100, Piede snodato



DOMI80
Accessori di collegamento, Leva di serraggio

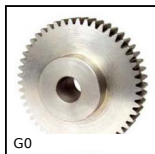

G0
Ingranaggio dritto acciaio, Acciaio 20NCD2



PVL
Volantino a lobi, Poliammide



RBN
Ruota, Rivestimento in gomma - nucleo in polipropilene



DOMI30
Accessori di collegamento, Piastra



TCC
Tenditore, Acciaio



GG3
Ingranaggio dritto rettificato, Acciaio trattato



CQA30
Accessori per slitta di regolazione miniatura, 30



VTHA
Vite magnetica a testa esagonale, Acciaio

Prodotti correlati



STRIP
Spazzola strip, Lunghezza 3m



STRIPF
Spazzola strip, Lunghezza 1m