


Sealing brush strips

FBL

Advantages and applications

Advantages


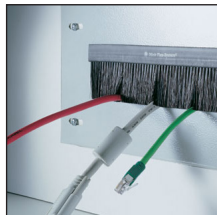


- No wastage, only the length required is removed from the roll.
- Reduced storage/transport space, each box contains 25 metres.

- Special scissors allow the strip to be cut to the required length.

- Flexible in terms of positioning and fitting.

Applications

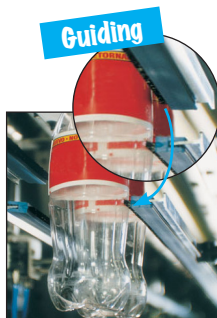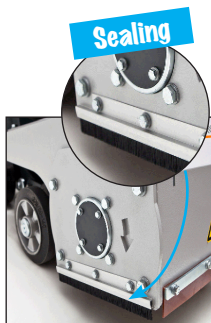

- Splash guard for wheel arches on a lorry

- Waterproofness of floor cleaning machines

- Guiding PET bottles

Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

FBL6000
FBL6001

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
 - **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- Maximum temperature: +150°C
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

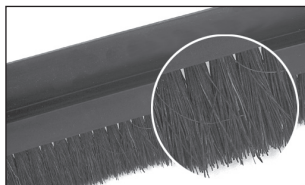

Horsehair fibres

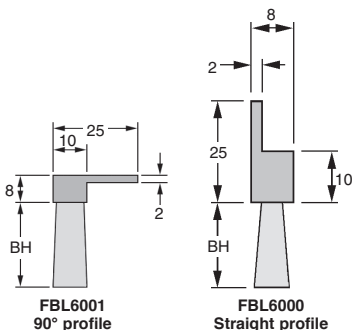

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
Black horsehair							
FBL6000-K19	0,2	15	5m	✓	-	63,64 €	-
FBL6000-K20	0,2	20	5m	✓	-	68,86 €	-
FBL6000-K21	FBL6001-K21	0,2	25	5m	-	✓	74,33 € 74,33 €
FBL6000-K23	FBL6001-K23	0,2	40	5m	✓	✓	92,79 € 92,79 €
FBL6000-K24	FBL6001-K24	0,2	50	5m	✓	✓	108,10 € 108,10 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip PA6 fibres Ø0.2 to Ø0.3 Stock

FBL6000 FBL6001

For ensuring an internal seal

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
- **Working temperature:** -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- **Working temperature:** -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

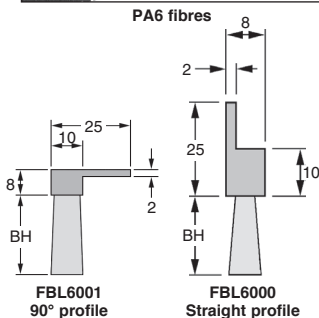

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres								
FBL6000-K1	FBL6001-K1	0,2	10	5m	✓	✓	48,53 €	48,53 €
FBL6000-K2	FBL6001-K2	0,2	15	5m	✓	✓	49,78 €	49,78 €
FBL6000-K3	FBL6001-K3	0,2	20	5m	✓	✓	51,26 €	51,26 €
FBL6000-K4	-	0,2	25	5m	✓	-	52,74 €	-
FBL6000-K5	FBL6001-K5	0,2	30	5m	✓	✓	54,21 €	54,21 €
FBL6000-K7	-	0,3	15	5m	✓	-	49,78 €	-
FBL6000-K8	-	0,3	20	5m	✓	-	51,26 €	-
FBL6000-K9	-	0,3	25	5m	✓	-	52,74 €	-
FBL6000-K10	-	0,3	30	5m	✓	-	54,21 €	-
FBL6000-K11	-	0,3	40	5m	✓	-	57,33 €	-
FBL6000-K12	-	0,3	50	5m	✓	-	60,29 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm



Brush strip PA6 fibres Ø0.3 to Ø0.5

For ensuring an internal seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length
FBL-TOOL



PA6 fibres

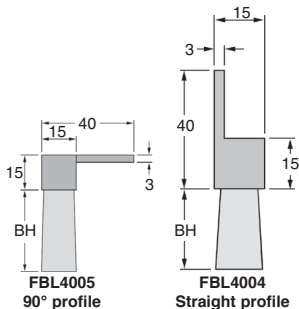

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
Black Polyamide 6 (PA6) fibres								
FBL4004-K8	-	0,3	20	5m	✓	-	140,75 €	-
FBL4004-K9	-	0,3	30	5m	✓	-	147,61 €	-
FBL4004-K13	-	0,5	30	5m	✓	-	147,61 €	-
FBL4004-K14	-	0,5	40	5m	✓	-	154,69 €	-
FBL4004-K15	-	0,5	50	5m	✓	-	161,80 €	-
FBL4004-K18	FBL4005-K15	0,5	80	5m	✓	✓	193,81 €	193,81 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip **PP fibres** Ø0.2



FBL6000 FBL6001

For ensuring an external seal

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts


Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals... Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals. Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL

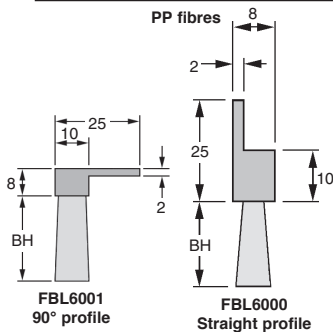

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Straight profile	90° profile	Bristle diameter (mm)	BH	Length	Stock*		Price each	
						Straight profile	90° profile	Straight profile	90° profile
Black horsehair									
FBL6000-K13	FBL6001-K13		0,2	10	5m	✓	✓	44,56 €	44,56 €
FBL6000-K14	FBL6001-K14		0,2	15	5m	✓	✓	44,98 €	44,98 €
FBL6000-K15	FBL6001-K15		0,2	20	5m	✓	✓	45,38 €	45,38 €
FBL6000-K17	FBL6001-K17		0,2	30	5m	✓	-	46,66 €	46,66 €
FBL6000-K18	FBL6001-K18		0,2	40	5m	✓	✓	47,69 €	47,69 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

For ensuring an external seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL

PP fibres

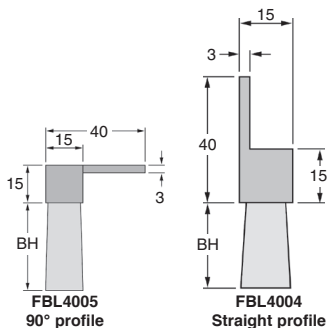**DISCOUNTS**

Qty	1+	2+	5+
Disc.	List	-10%	On request


Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres							
FBL4004-K34	-	0,3	30	5m	✓	-	130,13 €
FBL4004-K35	-	0,3	40	5m	✓	-	132,49 €
FBL4004-K36	FBL4005-K31	0,3	50	5m	✓	✓	134,99 €
FBL4004-K37	FBL4005-K32	0,3	60	5m	✓	-	137,47 €
FBL4004-K38	-	0,3	70	5m	✓	-	151,08 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Our other products

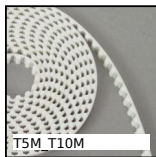

T type timing belt per metre, T5 Steel cored polyurethane



Elastic ringed latch, Hooks into a slot



Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



Internal epicyclic servo reducers, from 60 to 140 Nm




V shaped channel UtiliTrak®, V rail



Worm and wheel gear reducer, up to 298 Nm



End cap for round tube, Standard

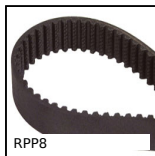

RPP heavy duty timing belt, RPP8



Mounting feet with integrated castors,



Worm - precision range, Steel



Speed controller 5A accessories, Kit of 4



Worm and wheel set, Hardened steel

Complementary products



Sealing brush strip, 3m length



Sealing brush strip, 1m length

Altri prodotti...




PNA_R
Giunto elastico
PERIFLEX, Collare di
ricambio



BAC110
Contenitore a becco,
Aggancio orientabile



CHM75
Riduttore a ruota e
vite senza fine, fino a
298 Nm

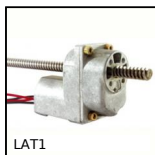

LAT1
Attuatore lineare a
motore, 1 ampere



BZY
Antivibrante elastico
cilindrico, Acciaio



HBM
Guida su semi-binari,
Boccola di regolazione



PRF JL2
Panel accessories,
Guarnizione - Ø 2mm



DBC
Panamech, Multi-
Beam, Alluminio - con
ganascia di serraggio




GB-RA
Ingranaggio dritto
ottone, Ottone
CuZn39Pb3



FF15
Riduttore ad alberi
paralleli, da 2.20 a 10
Nm



ZHBRA
Ingranaggio conico in
plastica, 1,25:1 2:1
3:1

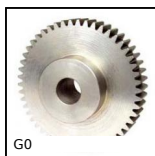

G0
Ingranaggio dritto
acciaio, Acciaio
20NCD2

Prodotti correlati



STRIP
Spazzola strip,
Lunghezza 3m



STRIPF
Spazzola strip,
Lunghezza 1m