

# Sealing brush strips

FBL

Advantages and applications


## Advantages



- No wastage, only the length required is removed from the roll.
- Reduced storage/transport space, each box contains 25 metres.



- Special scissors allow the strip to be cut to the required length.

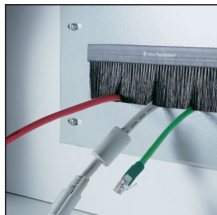


- Flexible in terms of positioning and fitting.


## Applications



- Splash guard for wheel arches on a lorry

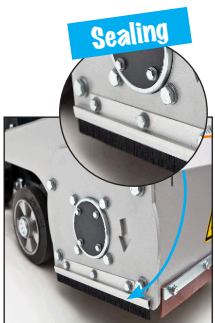

- Waterproofness of floor cleaning machines

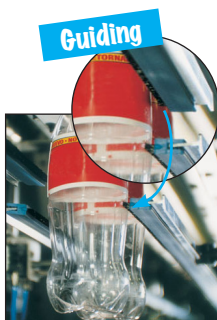

- Guiding PET bottles

# Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

**FBL6000**  
**FBL6001**

Brush strip to cut to desired length.

## Uses


- Sealing
- Cable entries
- Guiding parts

## Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
  - **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- Maximum temperature: +150°C  
Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
  - Maximum length of a single brush is 25 metres.
  - Special scissors for cutting to length
- FBL-TOOL**

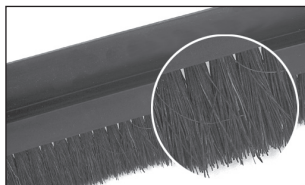

Horsehair fibres

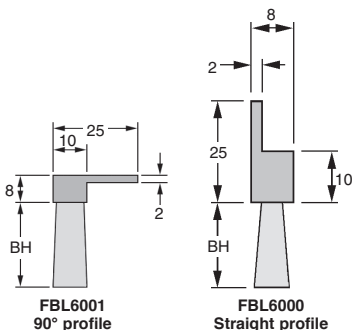

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
<b>Black horsehair</b>							
FBL6000-K19	0,2	15	5m	✓	-	63,64 €	-
FBL6000-K20	0,2	20	5m	✓	-	68,86 €	-
FBL6000-K21	FBL6001-K21	0,2	25	5m	-	✓	74,33 € 74,33 €
FBL6000-K23	FBL6001-K23	0,2	40	5m	✓	✓	92,79 € 92,79 €
FBL6000-K24	FBL6001-K24	0,2	50	5m	✓	✓	108,10 € 108,10 €

## Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm

# Brush strip PA6 fibres Ø0.2 to Ø0.3 Stock

## FBL6000 FBL6001

### For ensuring an internal seal

Brush strip to cut to desired length.

#### Uses


- Sealing
- Cable entries
- Guiding parts

#### Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
- **Working temperature:** -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- **Working temperature:** -40 to +125°C

#### Info.

- Sold in 5 metre lengths.
  - Maximum length of a single brush is 25 metres.
  - Special scissors for cutting to length
- FBL-TOOL**

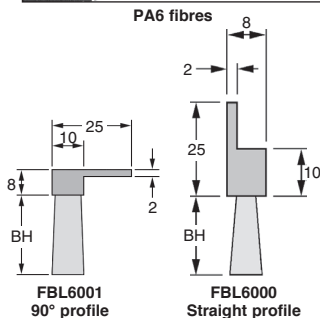

#### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
<b>Black Polyamide 6 (PA6) fibres</b>								
FBL6000-K1	FBL6001-K1	0,2	10	5m	✓	✓	48,53 €	48,53 €
FBL6000-K2	FBL6001-K2	0,2	15	5m	✓	✓	49,78 €	49,78 €
FBL6000-K3	FBL6001-K3	0,2	20	5m	✓	✓	51,26 €	51,26 €
FBL6000-K4	-	0,2	25	5m	✓	-	52,74 €	-
FBL6000-K5	FBL6001-K5	0,2	30	5m	✓	✓	54,21 €	54,21 €
FBL6000-K7	-	0,3	15	5m	✓	-	49,78 €	-
FBL6000-K8	-	0,3	20	5m	✓	-	51,26 €	-
FBL6000-K9	-	0,3	25	5m	✓	-	52,74 €	-
FBL6000-K10	-	0,3	30	5m	✓	-	54,21 €	-
FBL6000-K11	-	0,3	40	5m	✓	-	57,33 €	-
FBL6000-K12	-	0,3	50	5m	✓	-	60,29 €	-

#### Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm



# Brush strip PA6 fibres Ø0.3 to Ø0.5

For ensuring an internal seal

**FBL4004**  
**FBL4005**

Brush strip to cut to desired length.

## Uses

- Sealing
- Cable entries
- Guiding parts

## Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.  
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.  
Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length  
**FBL-TOOL**



PA6 fibres

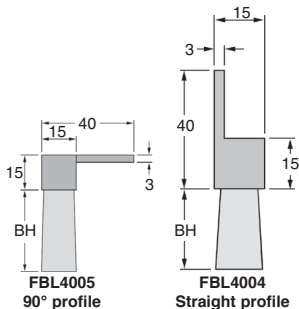

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
Straight profile	90° profile							
<b>Black Polyamide 6 (PA6) fibres</b>								
FBL4004-K8	-	0,3	20	5m	✓	-	140,75 €	-
FBL4004-K9	-	0,3	30	5m	✓	-	147,61 €	-
FBL4004-K13	-	0,5	30	5m	✓	-	147,61 €	-
FBL4004-K14	-	0,5	40	5m	✓	-	154,69 €	-
FBL4004-K15	-	0,5	50	5m	✓	-	161,80 €	-
FBL4004-K18	FBL4005-K15	0,5	80	5m	✓	✓	193,81 €	193,81 €

## Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm

# Brush strip **PP fibres** Ø0.2



**FBL6000**  
**FBL6001**

For ensuring an external seal

Brush strip to cut to desired length.

## Uses

- Sealing
- Cable entries
- Guiding parts


## Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals... Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals. Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

**FBL-TOOL**

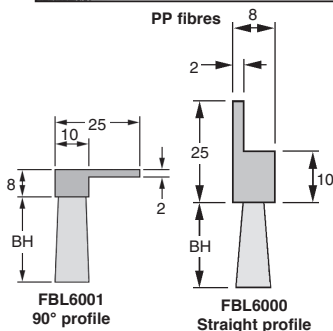

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Straight profile	90° profile	Bristle diameter (mm)	BH	Length	Stock*		Price each	
						Straight profile	90° profile	Straight profile	90° profile
<b>Black horsehair</b>									
FBL6000-K13	FBL6001-K13		0,2	10	5m	✓	✓	44,56 €	44,56 €
FBL6000-K14	FBL6001-K14		0,2	15	5m	✓	✓	44,98 €	44,98 €
FBL6000-K15	FBL6001-K15		0,2	20	5m	✓	✓	45,38 €	45,38 €
FBL6000-K17	FBL6001-K17		0,2	30	5m	✓	-	46,66 €	46,66 €
FBL6000-K18	FBL6001-K18		0,2	40	5m	✓	✓	47,69 €	47,69 €

## Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm

For ensuring an external seal

**FBL4004**  
**FBL4005**

Brush strip to cut to desired length.

**Uses**

- Sealing
- Cable entries
- Guiding parts

**Materials**


- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...  
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.  
Good UV and ozone resistance. Practically unaffected by most chemicals.  
Working temperature: -40 to +125°C

**Info.**

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

**FBL-TOOL**

PP fibres

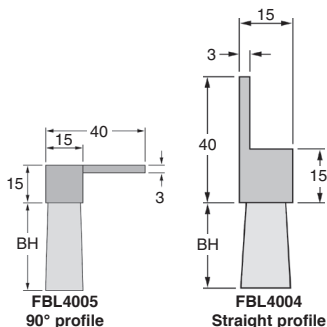**DISCOUNTS**

Qty	1+	2+	5+
Disc.	List	-10%	On request


Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
<b>Black Polyamide 6 (PA6) fibres</b>								
FBL4004-K34	-	0,3	30	5m	✓	-	130,13 €	-
FBL4004-K35	-	0,3	40	5m	✓	-	132,49 €	-
FBL4004-K36	FBL4005-K31	0,3	50	5m	✓	✓	134,99 €	134,99 €
FBL4004-K37	FBL4005-K32	0,3	60	5m	✓	-	137,47 €	137,47 €
FBL4004-K38	-	0,3	70	5m	✓	-	151,08 €	-

**Tools**

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm

## Our other products

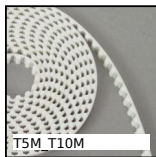

T type timing belt per metre, T5 Steel cored polyurethane



Elastic ringed latch, Hooks into a slot



Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



Internal epicyclic servo reducers, from 60 to 140 Nm




V shaped channel UtiliTrak®, V rail



Worm and wheel gear reducer, up to 298 Nm



End cap for round tube, Standard

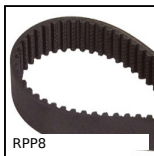

RPP heavy duty timing belt, RPP8



Mounting feet with integrated castors,



Worm - precision range, Steel



Speed controller 5A accessories, Kit of 4



Worm and wheel set, Hardened steel

## Complementary products



Sealing brush strip, 3m length



Sealing brush strip, 1m length

## Altri prodotti...



CHT

Motore AC asincrono trifase, 0.12 a 0.22kW



VTHA

Vite magnetica a testa esagonale, Acciaio



HBM

Guida su semi-binari, Boccola di regolazione



BPLE

Sfera portante a incastro, Leggero



RBN

Ruota, Rivestimento in gomma - nucleo in polipropilene



TS01\_TW01

Guida lineare su binario Drylin® T, fino al 7000 N



CHML40

Riduttore a ruota e vite senza fine, fino a 57 Nm - Con limitatore d...



SEH

Attrezzo di bloccaggio a tirante, A tirante - acciaio



SUA4\_L

Giunzione per catena al metro, Falsa maglia - acciaio



SLBS

Pistoncino a molla, Tutto inox



JCDss

Giunto cardanico - inox, Sollecitazioni leggere



UCF\_PBT

Cuscinetto a flangia quadrata polimero inox, Polimero e inox

## Prodotti correlati



STRIP

Spazzola strip, Lunghezza 3m



STRIPF

Spazzola strip, Lunghezza 1m