

# Sealing brush strips

FBL

Advantages and applications

## Advantages





- No wastage, only the length required is removed from the roll
- Reduced storage/transport space, each box contains 25 metres.

- Special scissors allow the strip to be cut to the required length.

- Flexible in terms of positioning and fitting.

## Applications

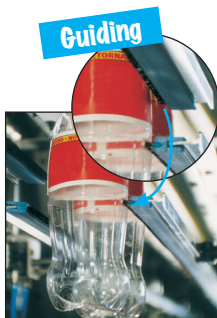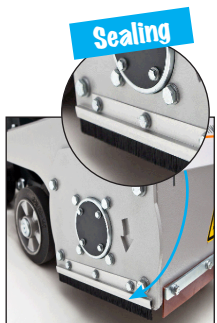

- Splash guard for wheel arches on a lorry

- Waterproofness of floor cleaning machines

- Guiding PET bottles

# Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

**FBL6000**  
**FBL6001**

Brush strip to cut to desired length.

## Uses


- Sealing
- Cable entries
- Guiding parts

## Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
  - **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- Maximum temperature: +150°C  
Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
  - Maximum length of a single brush is 25 metres.
  - Special scissors for cutting to length
- FBL-TOOL**

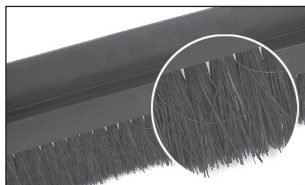

Horsehair fibres

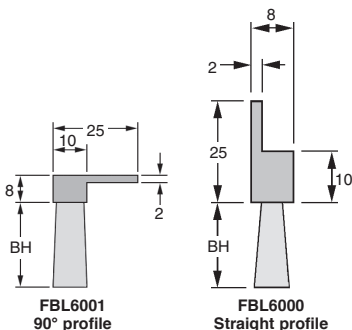

## DISCOUNTS

|       |      |      |            |
|-------|------|------|------------|
| Qty   | 1+   | 2+   | 5+         |
| Disc. | List | -10% | On request |

| Part number            | Bristle diameter (mm) | BH  | Length | Stock*           |             | Price each       |                   |
|------------------------|-----------------------|-----|--------|------------------|-------------|------------------|-------------------|
|                        |                       |     |        | Straight profile | 90° profile | Straight profile | 90° profile       |
| <b>Black horsehair</b> |                       |     |        |                  |             |                  |                   |
| FBL6000-K19            | 0,2                   | 15  | 5m     | ✓                | -           | 63,64 €          | -                 |
| FBL6000-K20            | 0,2                   | 20  | 5m     | ✓                | -           | 68,86 €          | -                 |
| FBL6000-K21            | FBL6001-K21           | 0,2 | 25     | 5m               | -           | ✓                | 74,33 € 74,33 €   |
| FBL6000-K23            | FBL6001-K23           | 0,2 | 40     | 5m               | ✓           | ✓                | 92,79 € 92,79 €   |
| FBL6000-K24            | FBL6001-K24           | 0,2 | 50     | 5m               | ✓           | ✓                | 108,10 € 108,10 € |

## Tools

|          |                  |          |
|----------|------------------|----------|
| FBL-TOOL | Cutting scissors | 193,51 € |
|----------|------------------|----------|

\*Depending on availability - Dimensions in mm

# Brush strip **PA6 fibres** Ø0.2 to Ø0.3 Stock

## FBL6000 FBL6001

### For ensuring an internal seal

Brush strip to cut to desired length.

#### Uses


- Sealing
- Cable entries
- Guiding parts

#### Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
- **Working temperature:** -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- **Working temperature:** -40 to +125°C

#### Info.

- Sold in 5 metre lengths.
  - Maximum length of a single brush is 25 metres.
  - Special scissors for cutting to length
- FBL-TOOL**

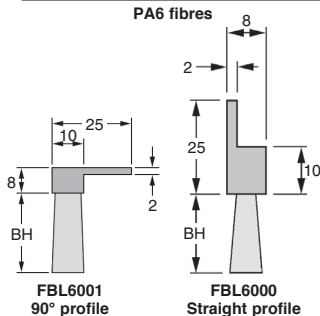

#### DISCOUNTS

|       |      |      |            |
|-------|------|------|------------|
| Qty   | 1+   | 2+   | 5+         |
| Disc. | List | -10% | On request |

| Part number                           |             | Bristle diameter (mm) | BH | Length | Stock*           |             | Price each       |             |
|---------------------------------------|-------------|-----------------------|----|--------|------------------|-------------|------------------|-------------|
| Straight profile                      | 90° profile |                       |    |        | Straight profile | 90° profile | Straight profile | 90° profile |
| <b>Black Polyamide 6 (PA6) fibres</b> |             |                       |    |        |                  |             |                  |             |
| FBL6000-K1                            | FBL6001-K1  | 0,2                   | 10 | 5m     | ✓                | ✓           | 48,53 €          | 48,53 €     |
| FBL6000-K2                            | FBL6001-K2  | 0,2                   | 15 | 5m     | ✓                | ✓           | 49,78 €          | 49,78 €     |
| FBL6000-K3                            | FBL6001-K3  | 0,2                   | 20 | 5m     | ✓                | ✓           | 51,26 €          | 51,26 €     |
| FBL6000-K4                            | -           | 0,2                   | 25 | 5m     | ✓                | -           | 52,74 €          | -           |
| FBL6000-K5                            | FBL6001-K5  | 0,2                   | 30 | 5m     | ✓                | ✓           | 54,21 €          | 54,21 €     |
| FBL6000-K7                            | -           | 0,3                   | 15 | 5m     | ✓                | -           | 49,78 €          | -           |
| FBL6000-K8                            | -           | 0,3                   | 20 | 5m     | ✓                | -           | 51,26 €          | -           |
| FBL6000-K9                            | -           | 0,3                   | 25 | 5m     | ✓                | -           | 52,74 €          | -           |
| FBL6000-K10                           | -           | 0,3                   | 30 | 5m     | ✓                | -           | 54,21 €          | -           |
| FBL6000-K11                           | -           | 0,3                   | 40 | 5m     | ✓                | -           | 57,33 €          | -           |
| FBL6000-K12                           | -           | 0,3                   | 50 | 5m     | ✓                | -           | 60,29 €          | -           |

#### Tools

|          |                  |          |
|----------|------------------|----------|
| FBL-TOOL | Cutting scissors | 193,51 € |
|----------|------------------|----------|

\*Depending on availability - Dimensions in mm



# Brush strip PA6 fibres Ø0.3 to Ø0.5

For ensuring an internal seal

**FBL4004**  
**FBL4005**

Brush strip to cut to desired length.

## Uses

- Sealing
- Cable entries
- Guiding parts

## Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.  
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.  
Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length  
**FBL-TOOL**



PA6 fibres

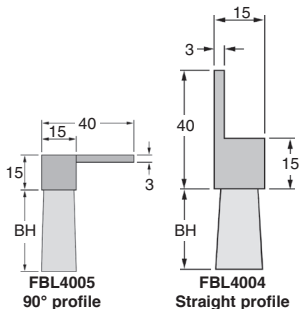

## DISCOUNTS

| Qty   | 1+   | 2+   | 5+         |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

| Part number                           | Bristle diameter (mm) | BH  | Length | Stock*           |             | Price each       |             |          |
|---------------------------------------|-----------------------|-----|--------|------------------|-------------|------------------|-------------|----------|
|                                       |                       |     |        | Straight profile | 90° profile | Straight profile | 90° profile |          |
| Straight profile                      | 90° profile           |     |        |                  |             |                  |             |          |
| <b>Black Polyamide 6 (PA6) fibres</b> |                       |     |        |                  |             |                  |             |          |
| FBL4004-K8                            | -                     | 0,3 | 20     | 5m               | ✓           | -                | 140,75 €    | -        |
| FBL4004-K9                            | -                     | 0,3 | 30     | 5m               | ✓           | -                | 147,61 €    | -        |
| FBL4004-K13                           | -                     | 0,5 | 30     | 5m               | ✓           | -                | 147,61 €    | -        |
| FBL4004-K14                           | -                     | 0,5 | 40     | 5m               | ✓           | -                | 154,69 €    | -        |
| FBL4004-K15                           | -                     | 0,5 | 50     | 5m               | ✓           | -                | 161,80 €    | -        |
| FBL4004-K18                           | FBL4005-K15           | 0,5 | 80     | 5m               | ✓           | ✓                | 193,81 €    | 193,81 € |

## Tools

|          |                  |          |
|----------|------------------|----------|
| FBL-TOOL | Cutting scissors | 193,51 € |
|----------|------------------|----------|

\*Depending on availability - Dimensions in mm

# Brush strip **PP fibres** Ø0.2



**FBL6000**  
**FBL6001**

For ensuring an external seal

Brush strip to cut to desired length.

## Uses

- Sealing
- Cable entries
- Guiding parts


## Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals... Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals. Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

**FBL-TOOL**

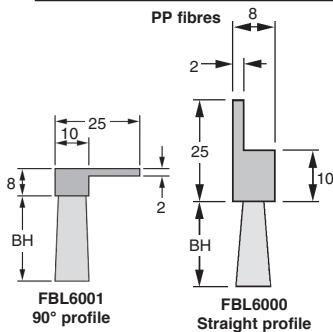

## DISCOUNTS

|       |      |      |            |
|-------|------|------|------------|
| Qty   | 1+   | 2+   | 5+         |
| Disc. | List | -10% | On request |

| Part number | Straight profile | 90° profile | Bristle diameter (mm) | BH | Length | Stock*           |             | Price each       |             |
|-------------|------------------|-------------|-----------------------|----|--------|------------------|-------------|------------------|-------------|
|             |                  |             |                       |    |        | Straight profile | 90° profile | Straight profile | 90° profile |

### Black horsehair

|             |             |     |    |    |   |   |         |         |
|-------------|-------------|-----|----|----|---|---|---------|---------|
| FBL6000-K13 | FBL6001-K13 | 0,2 | 10 | 5m | ✓ | ✓ | 44,56 € | 44,56 € |
| FBL6000-K14 | FBL6001-K14 | 0,2 | 15 | 5m | ✓ | ✓ | 44,98 € | 44,98 € |
| FBL6000-K15 | FBL6001-K15 | 0,2 | 20 | 5m | ✓ | ✓ | 45,38 € | 45,38 € |
| FBL6000-K17 | FBL6001-K17 | 0,2 | 30 | 5m | ✓ | - | 46,66 € | 46,66 € |
| FBL6000-K18 | FBL6001-K18 | 0,2 | 40 | 5m | ✓ | ✓ | 47,69 € | 47,69 € |

### Tools

|          |                  |          |
|----------|------------------|----------|
| FBL-TOOL | Cutting scissors | 193,51 € |
|----------|------------------|----------|

\*Depending on availability - Dimensions in mm

For ensuring an external seal

**FBL4004**  
**FBL4005**

Brush strip to cut to desired length.

**Uses**

- Sealing
- Cable entries
- Guiding parts

**Materials**


- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...  
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.  
Good UV and ozone resistance. Practically unaffected by most chemicals.  
Working temperature: -40 to +125°C

**Info.**

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

**FBL-TOOL**

PP fibres

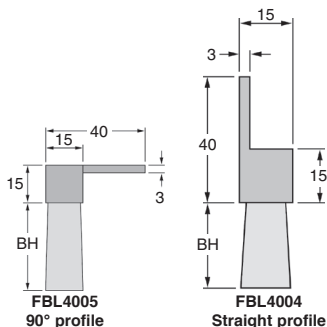**DISCOUNTS**

| Qty   | 1+   | 2+   | 5+         |
|-------|------|------|------------|
| Disc. | List | -10% | On request |


| Part number                           | Bristle diameter (mm) | BH  | Length | Stock*           |             | Price each       |             |
|---------------------------------------|-----------------------|-----|--------|------------------|-------------|------------------|-------------|
|                                       |                       |     |        | Straight profile | 90° profile | Straight profile | 90° profile |
| <b>Black Polyamide 6 (PA6) fibres</b> |                       |     |        |                  |             |                  |             |
| FBL4004-K34                           | -                     | 0,3 | 30     | 5m               | ✓           | -                | 130,13 €    |
| FBL4004-K35                           | -                     | 0,3 | 40     | 5m               | ✓           | -                | 132,49 €    |
| FBL4004-K36                           | FBL4005-K31           | 0,3 | 50     | 5m               | ✓           | ✓                | 134,99 €    |
| FBL4004-K37                           | FBL4005-K32           | 0,3 | 60     | 5m               | ✓           | -                | 137,47 €    |
| FBL4004-K38                           | -                     | 0,3 | 70     | 5m               | ✓           | -                | 151,08 €    |

**Tools**

|          |                  |          |
|----------|------------------|----------|
| FBL-TOOL | Cutting scissors | 193,51 € |
|----------|------------------|----------|

\*Depending on availability - Dimensions in mm

## Our other products

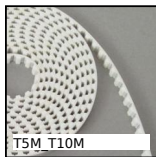

T type timing belt per metre, T5 Steel cored polyurethane



Elastic ringed latch, Hooks into a slot



Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



Internal epicyclic servo reducers, from 60 to 140 Nm




V shaped channel UtiliTrak®, V rail



Worm and wheel gear reducer, up to 298 Nm



End cap for round tube, Standard

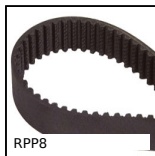

RPP heavy duty timing belt, RPP8



Mounting feet with integrated castors,



Worm - precision range, Steel



Speed controller 5A accessories, Kit of 4



Worm and wheel set, Hardened steel

## Complementary products



Sealing brush strip, 3m length



Sealing brush strip, 1m length

## Altri prodotti...



UGH50

Unità di guida tipo H,  
Per martinetti Ø 50



CHAFR-MINI

Cerniera, A frizione



CHAE6555

Cerniera ad avvitare  
estetica, Alluminio



AC

Piastrina di riscontro,  
15mm



RFV63

Riduttore inox a ruota  
e vite senza fine, fino  
a 152 Nm



ACLALF

Piede regolabile,  
Ideale per posti di  
lavoro



SSG0

Ingranaggio dritto  
Inox, Inox 304L



LWH

Guida lineare a sfere -  
Sfere acciaio, Binario -  
da 9320 N a 71300 N



MFBS

Giunto a soffietto  
Inox, Inox - con vite a  
pressione



G2

Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



M1

Coppia ruota e vite  
senza fine, Acciaio  
non temprato



PLM-20SC

Magnete cilindrico di  
fermo filettato,  
Magnete di fermo  
maschiato

## Prodotti correlati



STRIP

Spazzola strip,  
Lunghezza 3m



STRIPF

Spazzola strip,  
Lunghezza 1m