

FR For repairing damaged threads

Thread inserts are a convenient way of repairing siezed, damaged or hanging threads. It also allows renovate threads in high quality materials.

Thread inserts can be used in varying materials such as light alloys or cast materials.

Advantages

- Quick and easy to install
- Tangs are used during installation and then serve as an anti-rotation mechanism.
- **Apart from the insertion tool, no other special tools are required.**


Assembly

- **Some tapping required**
- Refer to technical oages for assembly/disassembly instructions



NEW!

Locking tang

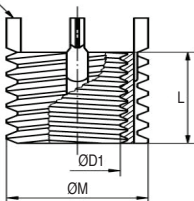

DISCOUNTS

Qty	1+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	On request

Part number	Thread ØD1	Thread ØM	Length L	Assembly drill size Ø	Assembly counterbore +0,25	Assembly thread	Min thread depth	Removal drill size Ø	Removal thread depth	Price each 1 to 9
FR-M5	M5	M8	8	6,9	8,3	M8	9,5	5,5	4,0	4,84 €
FR-M6	M6	M10x1,25	10	8,8	10,3	M10x1,25	11,5	7,5	4,8	5,24 €
FR-M8	M8	M12x1,25	12	10,8	12,3	M12x1,25	13,5	9,5	4,8	5,80 €
FR-M8x100	M8x1	M12x1,25	12	10,8	12,3	M12x1,25	13,5	9,5	4,8	5,80 €
FR-M10	M10	M14x1,5	14	12,8	14,3	M14x1,5	15,5	11,5	4,8	7,19 €
FR-M10x125	M10x1,25	M14x1,5	14	12,8	14,3	M14x1,5	15,5	11,5	4,8	7,19 €
FR-M12	M12	M16x1,5	16	14,8	16,3	M16x1,5	17,5	13,5	4,8	9,28 €
FR-M12x125	M12x1,25	M16x1,5	16	14,8	16,3	M16x1,5	17,5	13,5	4,8	9,28 €

Altri prodotti...



PDD

Pressore a molla
sensore di
rilevamento, Con asta
di comando per int...



HW_HT

Guida su semi-binari,
Binario



NT122

Riduttore coassiale a
treni paralleli, da 32 a
85 Nm - a treni paral...



PAP

Maniglia e battuta per
porta, Maniglia
ergonomica



P30

Riduttore a ruota e
vite senza fine, fino a
8.80 Nm



BFD

Perno ad innesto per
boccola, +180°C



UTKpwr

Guida lineare
Utilitrack®, Profilo
guida a V



PRF-P

Supporto piede, Per
piedi o ruote



BAC105

Contenitore a becco,
8mm



INS_SS

Inserito auto-filettante,
Inox 316



F7-SF-SM

Visualizzatore
multifunzione,
Supporto - montaggio



PTA50ssEB


Piede snodato con
base stampata Ø50,
Piede snodato

Prodotti correlati



FRtool

Attrezzi per inserti
filettati, Attrezzo di
posa

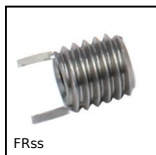

FRss

Inseriti filettati, Inox



INS

Boccola autofilettante
acciaio, acciaio



CHC

Vite a testa cava
esagonale CHC,
Acciaio classe 12.19