

# Latch clamp **with lock**



Lockable

GAC

- Snap closing
- Supplied with 2 identical keys
- Latch clamp and strike plates supplied separately
- Material:
  - Galvanised steel
  - Stainless steel 304

## Advantage

- Can be locked using a key

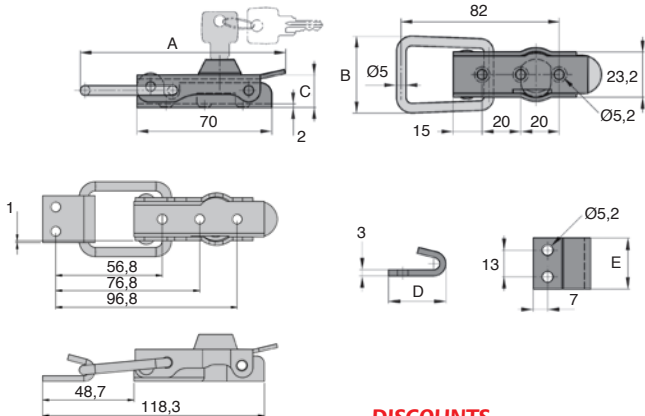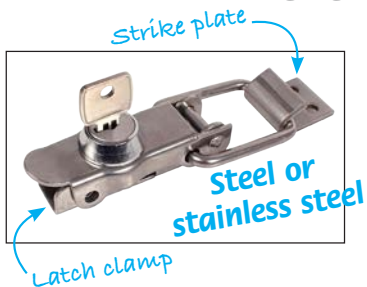

Hole layout

## DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc	List	-3%	-5%	-10%	On request

Part number	Material	Finish	A	B	C	D	E	Weight (g)	Stock*	Price each 1 to 9
<b>Latch clamp</b>										
GAC-106	steel	Galvanized	106,5	40,0	17,0	-	-	132	✓	17,59 €
GAC-106/SS	S/steel 304	Natural	106,5	40,0	17,0	-	-	132	✓	28,25 €
<b>Strike plate</b>										
GAC-106G	steel	Galvanized	-	-	-	28	25	24	✓	3,74 €
GAC-106G/SS	S/steel 304	Natural	-	-	-	28	25	24	✓	7,11 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Altri prodotti...




BLH60

Rinvio angolare a L,  
da 19 a 70 Nm



BABFCFO

Perno autobloccante,  
Bocche di fissaggio  
con flangia ovale

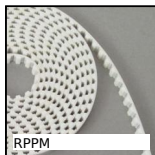

RPPM

Cinghia aperta al  
metro tipo RPP, RPP5  
Poliuretano armatura  
in acciaio



RTL450

Calettatore di  
bloccaggio, Coppia  
elevata



CHA1056\_U20

Cerniera ad avvitare,  
Sezione 76x50



PSG15

Ingranaggio dritto di  
precisione, Acciaio  
20NCD2 cementato  
temprato



PTA150

Piede snodato con  
base stampata Ø150,  
Ø 150



PSG05S

Ingranaggio dritto di  
precisione, Inox 303



CHAB

Hinge with stop,  
Hinge



CPAS-H

Squadra pieghevole,  
Per carico pesante



HTD8M\_20

Puleggia dentata di  
trasmissione tipo



D-PAR\_SS

Piedino antivibrante  
parabolico, inox

## Prodotti correlati



GAC

Chiusura a leva con  
serratura, Bloccabile