

To be fitted to a Ø8mm axle



GAL48



- Multiple rollers mounted on one axle work as a conventional roller with two possible directions of movement
- The "Snap in" function allows you to securely and quickly position two omni-directional rollers together, and guarantees an optimised assembly
- Corrosion-resistant
- Suitable for dusty environments
- No maintenance required
- Materials: technopolymer and stainless steel

Uses

- Control posts
- Assembly or handling stations

Info.

- Not sold individually, please contact us for details

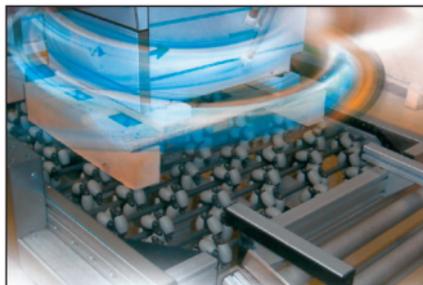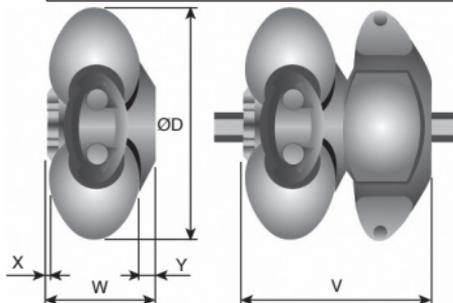

Typical application

Allows the load to be moved in any direction

DISCOUNTS

Qty.	1+	100+	300+	500+
Disc.	List	-30%	-40%	On request

Part number	ØD	X	Y	W	V	Max. load (daN)	Stock*	Price each 1 to 99
GAL48-OMNI	48	3	3	21,5	40	5	✓	7,57 €

*Depending on availability - Dimensions in mm

Altri prodotti...



H1

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



CHARcav

Cerniera a molla, to install



WJUM10

Pattino Drylin® W, Pattino



T5-16ECO

Puleggia dentata di posizionamento tipo T, Serie economica - T5 allu...



PLA

Magnete piatto, Magnete piatto



PT821

Pignone di trazione, Serie 821 e 805



RAM35

Riduttore manuale, Rinvio angolare



BLHB20

Rinvio angolare ad albero cavo, fino a 1.77 Nm



PITAss

Pistoncino a molla, con maniglia a T



TOC

Testa orientabile, Corta



PDM_PDV

Detectable plastic palm grip, by metal detectors



EKGS

Giunto senza gioco Gerwah®, da 0.5 a 35Nm

Prodotti correlati



RLX

Rullo folle plastica, PVC



RLXAC8

Rullo folle, Acciaio