

To be fitted to a Ø8mm axle



GAL48



- Multiple rollers mounted on one axle work as a conventional roller with two possible directions of movement
- The "Snap in" function allows you to securely and quickly position two omni-directional rollers together, and guarantees an optimised assembly
- Corrosion-resistant
- Suitable for dusty environments
- No maintenance required
- Materials: technopolymer and stainless steel

### Uses

- Control posts
- Assembly or handling stations

### Info.

- Not sold individually, please contact us for details

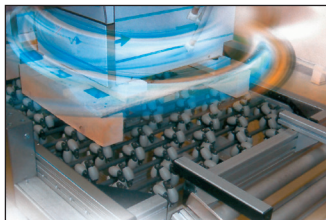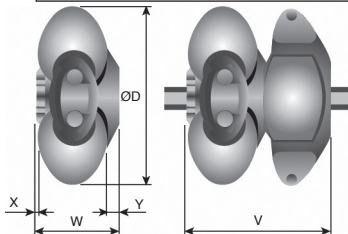

Typical application

Allows the load to be moved in any direction

### DISCOUNTS

Qty.	1+	100+	300+	500+
Disc.	List	-30%	-40%	On request

Part number	ØD	X	Y	W	V	Max. load (daN)	Stock*	Price each 1 to 99
GAL48-OMNI	48	3	3	21,5	40	5	✓	7,57 €

\*Depending on availability - Dimensions in mm


## Altri prodotti...



Ventosa, silicone



Catena a tapparella dritta, Larga serie 805

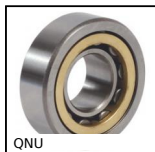

Cuscinetto a singola corona di rulli cilindrici, Anello interno libero



Giunto cardanico doppio serie eco, Sollecitazioni leggere



Copiglia per tubo, Clip per tubo



Riduttore coassiale a treni paralleli, da 0.57 a 2.25 Nm - a treni p...



Accessori per slitta di regolazione miniatura, 30



Rinvio angolare a T, da 1.65 a 4.40 Nm



Accessori per pannelli, Morsetto di fissaggio



Ingranaggio dritto acciaio - serie ECO, Acciaio C45



Boccola di fermo per perno ad innesto, Acciaio nichelato



Chiusura 1/4 di giro - Piastra di bloccaggio, Montaggio ad incastro

## Prodotti correlati



Rullo folle plastica, PVC



Rullo folle, Acciaio