

To be fitted to a Ø8mm axle



GAL48



- Multiple rollers mounted on one axle work as a conventional roller with two possible directions of movement
- The "Snap in" function allows you to securely and quickly position two omni-directional rollers together, and guarantees an optimised assembly
- Corrosion-resistant
- Suitable for dusty environments
- No maintenance required
- Materials: technopolymer and stainless steel

### Uses

- Control posts
- Assembly or handling stations

### Info.

- Not sold individually, please contact us for details

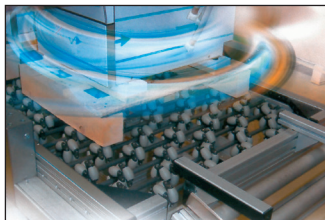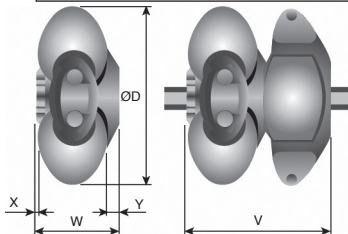

Typical application

Allows the load to be moved in any direction

### DISCOUNTS

Qty.	1+	100+	300+	500+
Disc.	List	-30%	-40%	On request

Part number	ØD	X	Y	W	V	Max. load (daN)	Stock*	Price each 1 to 99
GAL48-OMNI	48	3	3	21,5	40	5	✓	7,57 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



BOXKK

Box kit di chiavette,  
Box kit - Acciaio o  
inox



ADL\_F

Anello di  
sollevamento, Inox



UGPC

Unità di guida per  
cilindrico, Cuscinetto  
corto



EHD08-9

Riduttore coassiale,  
da 35 a 50 Nm



MCL

Manicotto cilindrico  
maschiato, Cilindrico -  
inox




PR820

Ruota di rinvio, Serie  
820 e 815



PCM

Impugnatura cilindrica  
fissa, Impugnatura  
non girevole

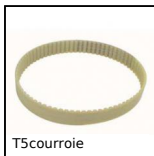


T5courroie

Cinghia di  
posizionamento T, T5  
Poliuretano armatura  
in acciaio




BAP25

Anello di bloccaggio,  
Ø25 - Ø40

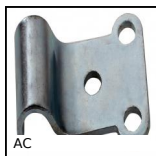

AC

Piastrina di riscontro,  
15mm

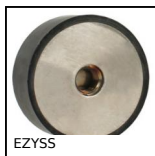

EZYSS

Piedino antivibrante  
cilindrico inox, inox



AC

Piastrina di riscontro,  
12,13,18 e 20mm

## Prodotti correlati



RLX

Rullo folle plastica,  
PVC



RLXAC8

Rullo folle, Acciaio