



- Nut for use with a ballscrew
- Axial backlash: 0.05 mm for screws with 5mm pitch 0.1 mm for screws with 5mm pitch
- Material:
16 MnCr5 or 100 Cr6

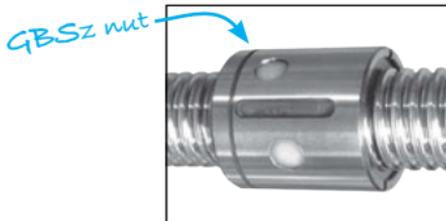

Accessories

- Please see the **KGS** ballscrew
The pitch and diameter must be the same as that of the nut)

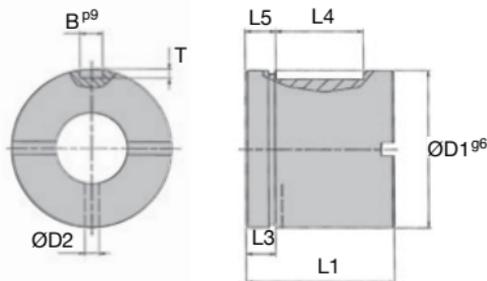

DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	ØD1g6	ØD2	L1	L3	L4	L5	BxT
GBS-Z-2005-RH	32	3	34	6,75	20	7	5x2
GBS-Z-2505-RH	38	3	34	6,75	20	7	5x2
GBS-Z-3205-RH	45	3	45	7,25	30	7,5	6x2,5
GBS-Z-3210-RH	53	3	60	10	30	15	6x2,5
GBS-Z-4005-RH	53	3	45	7,25	30	7,5	6x2,5
GBS-Z-5010-RH	72	4	82	11	36	23	6x2,5
GBS-Z-6310-RH	85	4	82	11	36	23	6x2,5

Part number	For screw		Load		Weight (kg)	Price each
	Ø	Travel per revolution (mm)	dynamic C (kN)	static Co (kN)		
GBS-Z-2005-RH	20	5	8,00	17,00	0,15	167,73 €
GBS-Z-2505-RH	25	5	9,50	22,40	0,20	191,27 €
GBS-Z-3205-RH	32	5	17,00	49,00	0,30	271,67 €
GBS-Z-3210-RH	32	10	25,70	56,00	0,60	320,19 €
GBS-Z-4005-RH	40	5	19,00	63,50	0,50	342,63 €
GBS-Z-5010-RH	50	10	55,00	153,00	1,10	447,16 €
GBS-Z-6310-RH	63	10	60,00	200,00	1,50	754,68 €

Dimensions in mm

Altri prodotti...



CHA138

Cerniera ad avvitare,
138 gradi



PAS

Maniglia a ponte,
Reinforced PA
thermoplastic




LSAG

Albero scanalato a
sfere, Binario - da 514
N a 15386 N



T5P_T10P

Piastra di giunzione
per cinghia T, T10

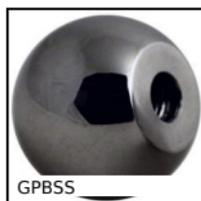

GPBSS

Impugnatura sferica
femmina filettata,
Inox 304



GET-AL

Giunto elastico
alluminio serie eco.,
Alluminio



WFRM

Dado trapezoidale,
Polimero (Iglidur®) - 1
filetto



HRV

Sistema di guida su
binario a V Simple
Select®, Binario con
carrello



FF10

Riduttore ad alberi
paralleli, da 0.78 a
3.70 Nm



BCM_MPBT

Spazzola cilindrica
modulare, Filo
poliestere PBT



PAT123

Piede snodato con
base lamiera Ø123, Ø
123



CLQ

Cuscinetti a sfere -
Accessorio, Spessori
metallici centesimali a
na...

Prodotti correlati



KGS

Vite a ricircolo di sfere
al metro, Vite a sfere
rullata, al metro



GBS

Dado per vite a sfere,
Dado flangiato