



- Nut for use with a ballscrew
- Axial backlash: 0.05 mm for screws with 5mm pitch 0.1 mm for screws with 5mm pitch
- Material:
16 MnCr5 or 100 Cr6

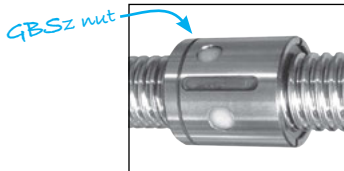

Accessories

- Please see the **KGS** ballscrew
The pitch and diameter must be the same as that of the nut)

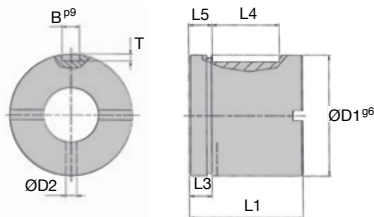

DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	ØD1 ⁹⁶	ØD2	L1	L3	L4	L5	BxT
GBS-Z-2005-RH	32	3	34	6,75	20	7	5x2
GBS-Z-2505-RH	38	3	34	6,75	20	7	5x2
GBS-Z-3205-RH	45	3	45	7,25	30	7,5	6x2,5
GBS-Z-3210-RH	53	3	60	10	30	15	6x2,5
GBS-Z-4005-RH	53	3	45	7,25	30	7,5	6x2,5
GBS-Z-5010-RH	72	4	82	11	36	23	6x2,5
GBS-Z-6310-RH	85	4	82	11	36	23	6x2,5

Part number	For screw		Load		Weight (kg)	Price each
	Ø	Travel per revolution (mm)	dynamic C (kN)	static Co (kN)		
GBS-Z-2005-RH	20	5	8,00	17,00	0,15	167,73 €
GBS-Z-2505-RH	25	5	9,50	22,40	0,20	191,27 €
GBS-Z-3205-RH	32	5	17,00	49,00	0,30	271,67 €
GBS-Z-3210-RH	32	10	25,70	56,00	0,60	320,19 €
GBS-Z-4005-RH	40	5	19,00	63,50	0,50	342,63 €
GBS-Z-5010-RH	50	10	55,00	153,00	1,10	447,16 €
GBS-Z-6310-RH	63	10	60,00	200,00	1,50	754,68 €

Dimensions in mm

Altri prodotti...



GE_ES
Snodo sferico,
acciaio/acciaio



PR882
Ruota di rinvio, Serie
882



RURT
Ruota girevole a foro
centrale, Poliuretano -
Mozzo alluminio
(Ultra...



RAM30
Riduttore manuale,
Rinvio angolare



RHT
Ruota alte
temperature, fino a
200kg



S_2RS
Cuscinetto radiale a
sfere, Inox




T5P_T10P
Piastra di giunzione
per cinghia T, T10




DOMI80
Kit di raccordo, Kit di
raccordo XY



HLUMss
Impugnatura girevole,
Inox 316

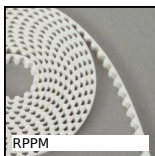

RPPM
Cinghia aperta al
metro tipo RPP, RPP8
Poliuretano armatura
in acciaio

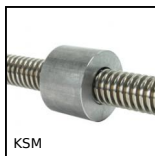


KSM
Dado cilindrico in
acciaio, Acciaio - 1
filetto



RFVcap
Coperchio di
protezione inox,
Coperchio di
protezione aperto

Prodotti correlati

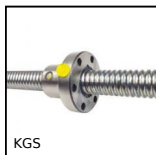

KGS
Vite a ricircolo di sfere
al metro, Vite a sfere
rullata, al metro



GBS
Dado per vite a sfere,
Dado flangiato